

SUMMARY

Wires

Low voltage 1



Image is for illustrative purpose only

Series 00
Termination type Male solder
IP rating 50
AWG wire size 28.00 - 20.00
Cable Ø 3.30 - 4.10 mm
Status **obsolete**
Matching parts [ERA.00.113.CTL](#)

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model FFA*: Straight plug with oversize cable collet and nut for fitting a bend relief
Keying Circular, male
Housing Material Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Variant Z : Nut for fitting a bend relief
Weight 5.95 g

Performance

Configuration 00.113 : 1 Low Voltage
Insulator T: PTFE
Rated Current 8 Amps

Specifications


Contact Type: Solder
Vtest: 850 V (AC), 1200 V (DC)

Others

Salt Spray Corrosion: >1000 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

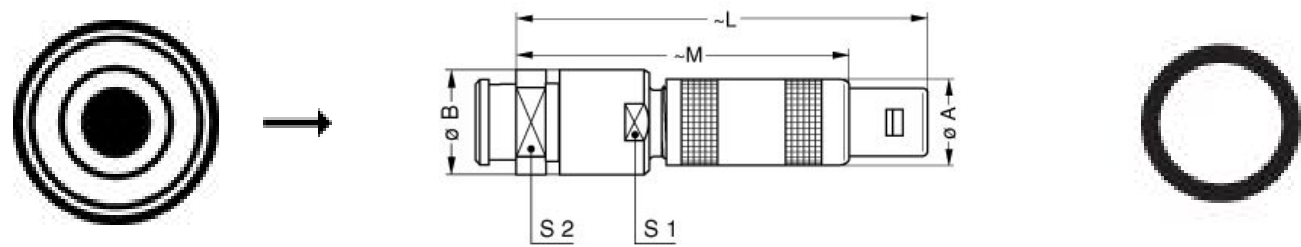

Dimensions

	A	B	L	M	S1	S2
mm.	6.4	8	44	36	7	6.5
in.	0,25	0,31	1,73	1,42	0,28	0,26

RECOMMENDED BY LEMO

Tools

Spanner wrench: [DCD.00.003.PA060](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.