

Actuator

45-
2845.2E90.002



<https://eao.com/p/45-2845.2E90.002>

Your product:



45-2845.2E90.002 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front bezel colour:	Silver
Front bezel material:	Metal

MOUNTING

Design:	raised
---------	--------

OPERATING-/INDICATION PART

Lever colour:	White
Lever shape:	round
Lever material:	plastic

MECHANICAL CHARACTERISTIC

Weight:	0.001 kg
Switching action:	Maintained - Maintained - Maintained - Maintained
Switching positions:	4 positions
Mechanical lifetime:	1 Mio. cycles of operation
Operating frequency:	1 800/h

AMBIENT CONDITION

IP front protection:	IP66, IP67, IP69K
Operating temperature:	- 25 °C ... + 70 °C


Storage temperature:	– 40 °C ... + 80 °C
Climate resistance:	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6
Shock resistance:	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms
Vibration resistance:	According to IEC 60068-2-6: 10 ... 500 Hz: 5 g

OTHER


Housing material:	Metal
Short Description:	Actuator, Ø 29,5 mm, optional illuminative, White, round, Silver, Metal, Maintained - Maintained - Maintained - Maintained, IP66, IP67, IP69K
Wiring diagrams:	



Dimension drawings:

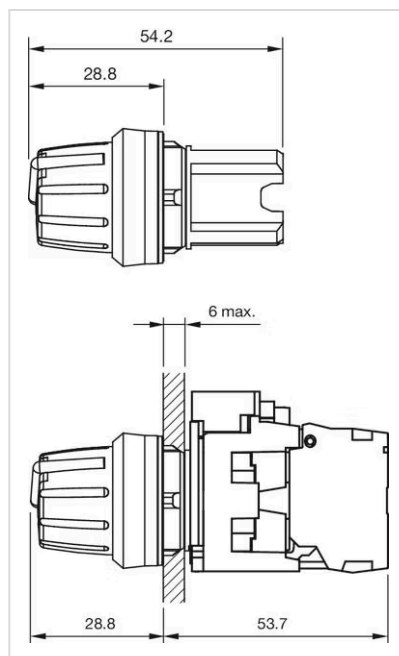

Mounting cut-outs:

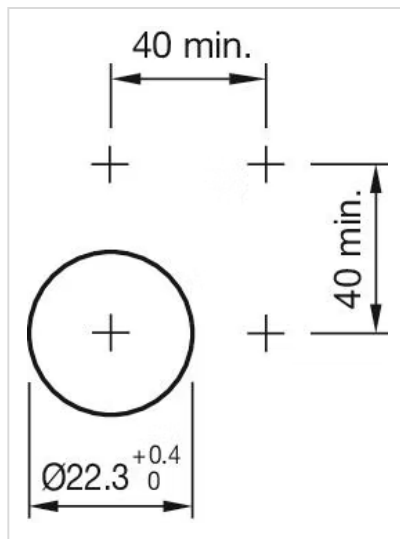

Switching positions:

