



(2.00 mm) .0787"

MTMM-114-05-F-Q-235

MTMM-108-07-F-D-350

MTMM-124-15-T-S-650

MTMM SERIES

MODIFIED THROUGH-HOLE HEADER

SPECIFICATIONS

For complete specifications see www.samtec.com?MTMM

Insulator Material:

Black Liquid Crystal Polymer

Terminal Material:

Phosphor Bronze

Plating:

Sn or Au over
50 μ " (1.27 μ m) Ni

Operating Temp Range:

-55 °C to +105 °C with Tin;

-55 °C to +125 °C with Gold

RoHS Compliant:

Yes

Lead-Free Solderable:

Yes

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



FILE NO. E111594

ALSO AVAILABLE (MOQ Required)


- Other platings
Contact Samtec.

Board Mates:
CLT, SQT, SQW, ESQT,
TLE, SMM, MMS



Cable Mates:
TCSD

Choice of
single, double or
quad row

Specify
post height in
(0.13 mm) .005"
increments

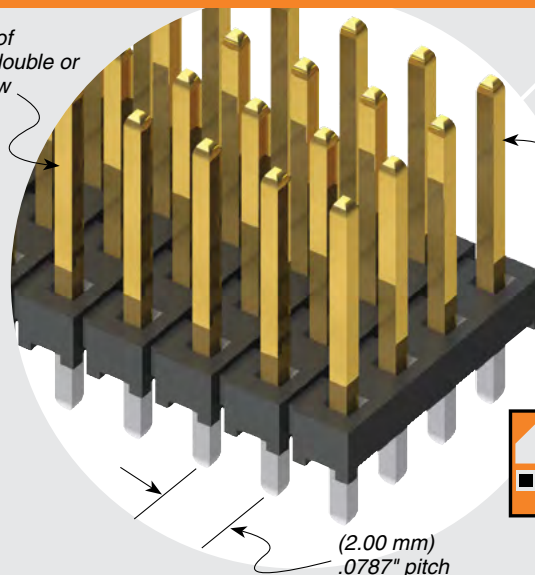

(2.00 mm)
.0787" pitch

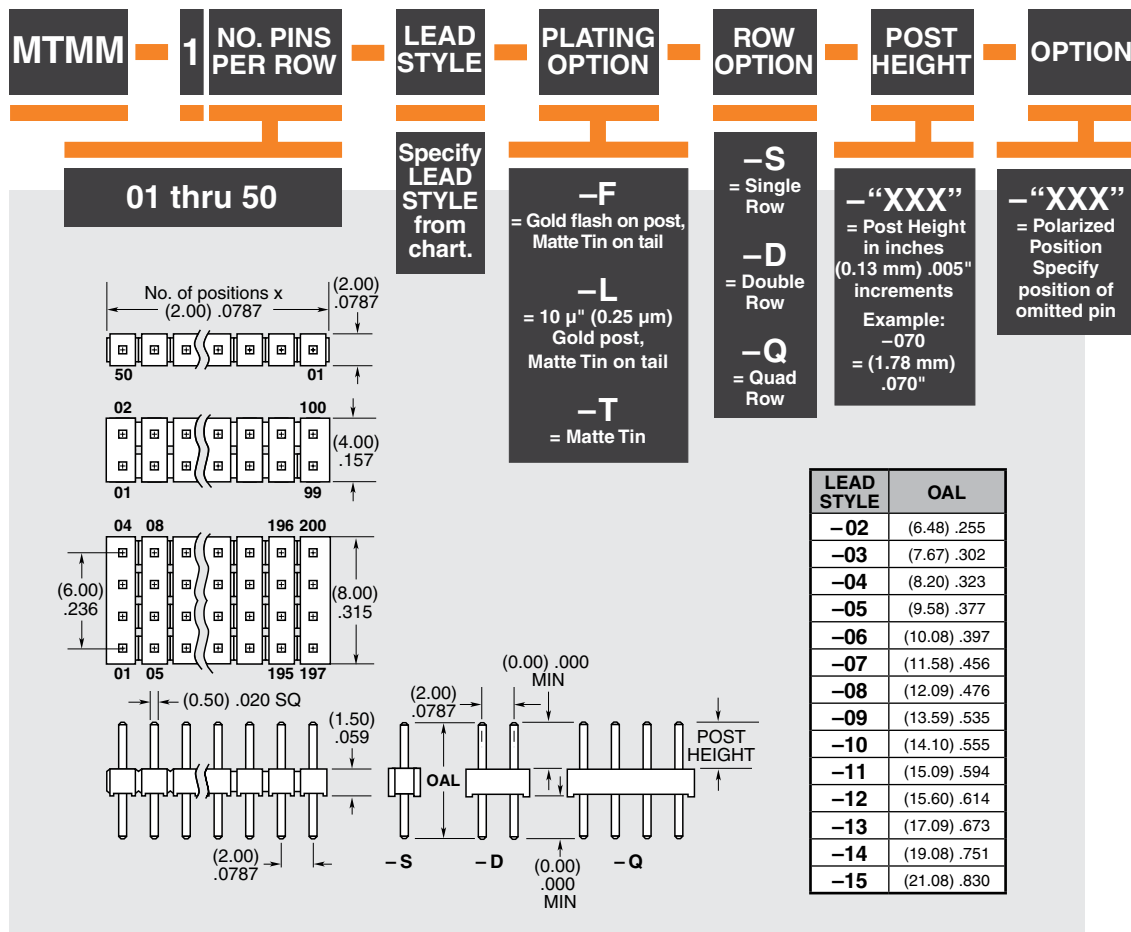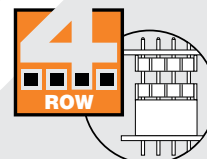

Note: This Series is non-standard, non-returnable.