
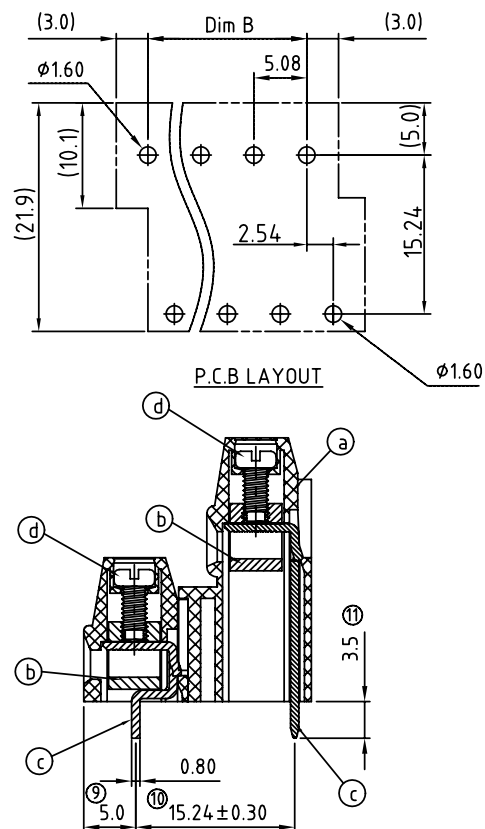


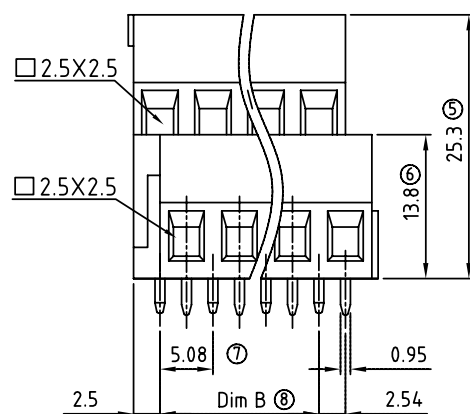

Material

- Item a Terminal housing :Thermoplastic (UL 94V-0)
- Item b Clamp : Brass Ni plated
- Item c Wire guard solder pin :Brass ,Tin plated
- Item d Terminal screw: Steel Zinc plating"-slot type

Electrical

- Voltage rating: 300VAC
- Current rating: 20A
- Wire range:
- Solid wire(AWG): 12-22
- Stranded wire(AWG): 12-22
- Torque(Lb-In): 3.5
- Screw: M2.5
- Wire strip length: 6-7mm
- Withstanding Voltage: 1.6KV
- Operating temperature: -40°C to +115°C
- Soldering temperature: 250°C±10°C/5 Sec
- Safety Approval:

△ YL xx 6 1 x 0 xxxx G

04	2x2 CONTACTS
06	2x3 CONTACTS
...	...
48	2x24 CONTACTS
64	2x32 CONTACTS

COLOR

0:	BLACK
5:	GREEN
6:	BLUE
8:	GREY

0000 @ logo R
000A ANYTEK logo
(Steel screw plating Cr³⁺)
Any special item by
customer request,
please contact sales
department.

RoHS pb<40 , 000ppm

Poles	2x2	2x3	2x4	2x5	2x6	2x7	2x8	2x9	2x10	2x11	2x12	2x13
Dim L	10.16	15.24	20.32	25.40	30.48	35.56	40.64	45.72	50.80	55.88	60.96	66.04
Dim B	5.08	10.16	15.24	20.32	25.40	30.48	35.56	40.64	45.72	50.80	55.88	60.96
TOL	± 0.20					± 0.30						± 0.35
Poles	2x14	2x15	2x16	2x17	2x18	2x19	2x20	2x21	2x22	2x23	2x24	
Dim L	71.12	76.20	81.28	86.36	91.44	96.52	101.60	106.68	111.76	116.84	121.92	
Dim B	66.04	71.12	76.20	81.28	86.36	91.44	96.52	101.60	106.68	111.76	116.84	
TOL	± 0.35					± 0.40						

ANYTEK

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE		YL-5.08mm Series “-” Right			
PART NO.		YLxx61x00000G		DWG NO.	8YL0102
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.	Tolerance
		Jacke 2009.03.25	Jacke 2009.03.25		UNIT: mm X. ±0.50
					SCALE: NONE X.X ±0.30
				SHEET: 01/01	REV: E X.XX ±0.10
					X° ±1°