

Actuator

45-
2F0V.1010.000



<https://eao.com/p/45-2F0V.1010.000>

Your product:



45-2F0V.1010.000 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	raised
---------	--------

OPERATING-/INDICATION PART

Lever colour:	Black
Lever material:	plastic

MECHANICAL CHARACTERISTIC

Weight:	0.085 kg
Switching action:	Momentary
Mechanical lifetime:	250 000 cycles of operation per direction of actuation

AMBIENT CONDITION

IP front protection:	IP65, IP67
Operating temperature:	– 25 °C ... + 70 °C
Storage temperature:	– 40 °C ... + 80 °C
Climate resistance:	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6, 3B2
Shock resistance:	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

Vibration resistance:

According to IEC 60068-2-6: 10 ... 500 Hz: 5 g

OTHER**Housing material:**

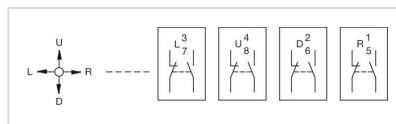
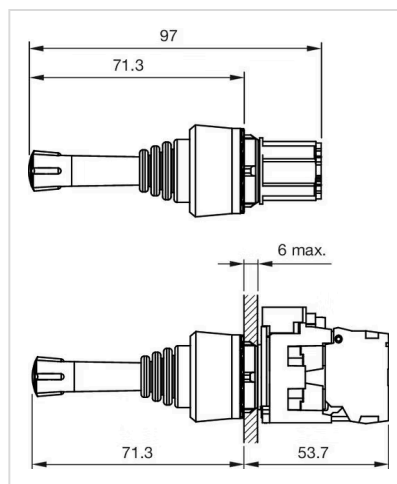
Plastic

Short Description:

Actuator, Ø 29,5 mm, Black, Black, Plastic, Momentary, IP65, IP67

Hints:

Lockable only in center position

Wiring diagrams:**Dimension drawings:****Mounting cut-outs:**