



ENM2 Series

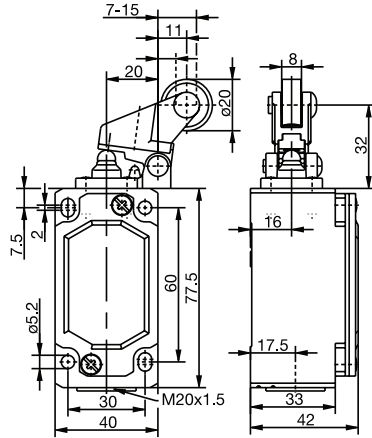

DGKW RO20





AD (Form D)

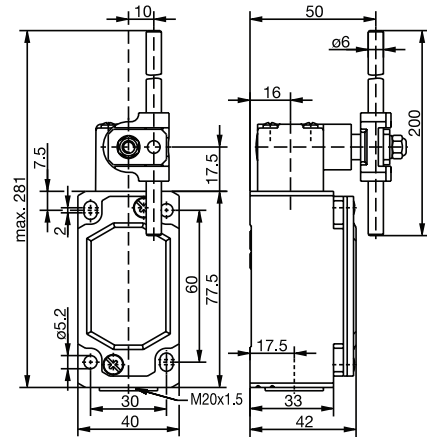

Switching Operation

1 NC / 1 NO Contacts

  608.7127.010 ENM2-U1Z DGKW RO20
608.7377.011 ENM2-SU1Z DGKW RO20



2 NC Contacts

-

-

2 NO Contacts

-

-

1 NC / 1 NO Contacts Overlapping

-

-

Replacement actuator:

391.8271.655

Technical Information

	Slow Action	Snap Action
Maximum Switching Voltage	240V	240V
Max. Switching Amps (up to)*	10A	10A
B10d (up to)*	20 Million	20 Million
Mechanical Service Life (up to)*	10 x 10 ⁶	10 x 10 ⁶
Switching Frequency	≤ 100/min	≤ 100/min
Operating Temperature	-30 °C to +80 °C	-30 °C to +80 °C
Protection Rating	IP65	IP65
Utilization Category (up to)*	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
Rate Insulation Voltage	400VAC	400VAC

Approvals

* Depending on switching system - see technical information for details

 


Special features/variants (on request)

- Available with different actuating directions


Slow Action

608.7137.018 ENM2-U1 AD



Snap Action

 608.7387.019 ENM2-SU1 AD



-

-

-

-

-

-

391.8370.731

Slow Action

	Slow Action	Snap Action
240V	240V	240V
10A	10A	10A
20 Million	20 Million	20 Million
10 x 10 ⁶	10 x 10 ⁶	10 x 10 ⁶
≤ 100/min	≤ 100/min	≤ 100/min
-30 °C to +80 °C	-30 °C to +80 °C	-30 °C to +80 °C
IP65	IP65	IP65
AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A	AC-15, Ue/Ue 240V 3A
400VAC	400VAC	400VAC



Special features/variants (on request)

- Available with various actuator lengths and actuator directions

Drawing dimensions in mm