

780-522-DPX34R G 6 - WS C

Product Series ————
 Basic Number ————
 Connector Type ————
 Attachment Rope ————
 G = Nylon Rope
 (Omit for None)



C = Conductive
 (Omit for Standard)

Attachment Type (Table I)

Attachment Length in Inches
 (± .250 [6.35] Inch)





*“To Protect
and to Serve”*

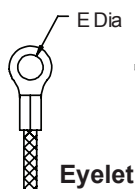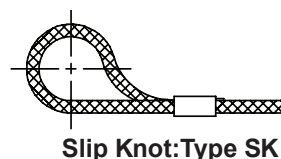

**Plastic Tie Strap:
Type WS**

See Part
Number
Development

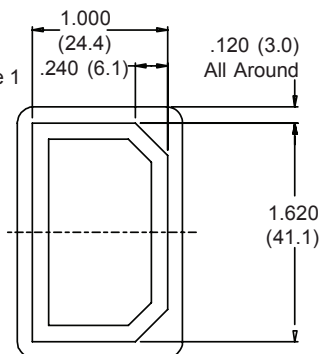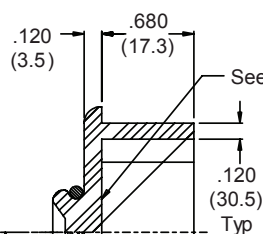

DPX34R Shown

**TABLE I:
ATTACHMENT
TYPE**

Dash No.	E Dia ±.010 (0.3)
00	No Terminal
01	.140 (3.6)
02	.182 (4.6)
03	.191 (4.9)
04	.197 (5.0)
05	.167 (4.2)
06	.125 (3.2)
07	.218 (5.5)
09	.156 (4.0)
WS	With Strap
SK	Slip Knot

NOTES:

1. Cover identified in area shown.
2. Metric dimensions (mm) are indicated in parentheses.
3. This series of covers is similar to Bean Rubber Mfg. Co. BP-DPX34R-WC equivalent to 780-522-DPX34RG12-09.
4. Standard material contains trace amounts of sulfur (a vulcanizing agent) which is known to contribute to degradation/corrosion of silver plated components such as braid, etc. Specify MOD Code suffix -675 for sulfur-free material.
5. Standard material contains trace amounts of sulfur (a vulcanizing agent) which is known to contribute to degradation/corrosion of silver plated components such as braid, etc. Specify MOD Code suffix -678 for sulfur-free material.