

(2.00 mm) .0787"

MMT-120-02-L-SH

MMT-107-01-L-MT

MMT-130-02-L-DH

MMT SERIES

HORIZONTAL SURFACE MOUNT HEADER

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com/MMT

Insulator Material:

Black Liquid Crystal Polymer

Terminal Material:

Phosphor Bronze

Plating:

Au or Sn over

50 μ " (1.27 μ m) Ni

Operating Temp Range:

-55 °C to +105 °C with Tin;

-55 °C to +125 °C with Gold

RoHS Compliant:

Yes

PROCESSING

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0.10 mm) .004" max (02-25)

(0.15 mm) .006" max (26-36)

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



ALSO AVAILABLE (MOQ Required)


- Alignment pins
 - Locking clips
 - Molded pick & place pads
 - Other platings
- Contact Samtec.

Board Mates:
CLT, SQT, SQW, ESQT,
TLE, SMM, MMS

Cable Mates:
TCSD

Available with
optional
pick & place pads


APPLICATIONS

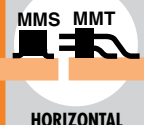

Single or
double row

(2.00 mm)
.0787" pitch

Surface mount
and mixed
technology
options

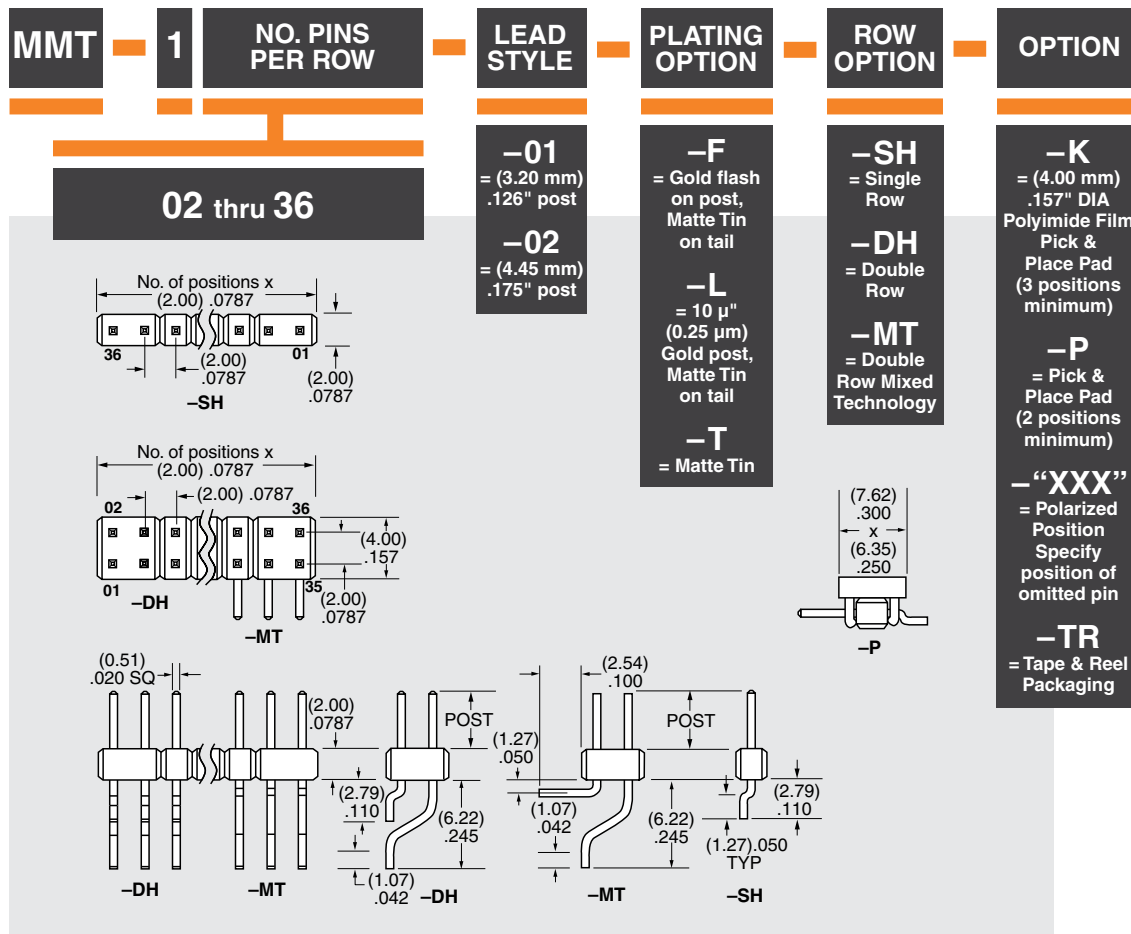

Note: Some lengths, styles and options are non-standard, non-returnable.