



SN2 Series

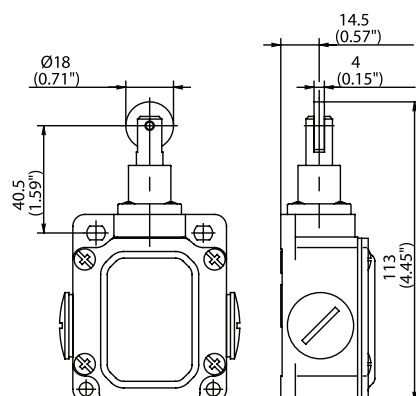

RIW



AHS

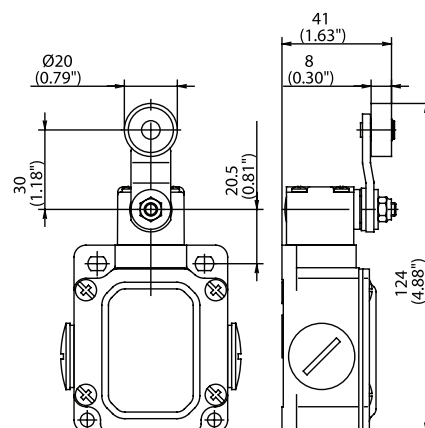


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 603.3117.025
SN2-U1Z RIW




Snap Action

 603.3367.017
SN2-SU1Z RIW




Slow Action

 603.3135.002
SN2-U1Z AHS




Snap Action

 603.3385.018
SN2-SU1Z AHS



2 NC Contacts

 603.3818.038
SN2-A2Z RIW



-
-

-
-

-
-

2 NO Contacts

-
-

-
-

-
-

-
-

1 NC / 1 NO Contacts Overlapping

-
-

-
-

-
-

-
-

Replacement actuator:

391.8170.587

391.3351.913

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

3 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals



Special features/variants (on request)

- Available with different actuating directions
- With latching function

Special features/variants (on request)

- Available with different actuating directions

Drawing dimensions in mm