

Actuator

704.099.0



<https://eao.com/p/704.099.0>

Your product:



704.099.0 Actuator

FRONT

Front dimension:	Ø 29 mm
Front bezel colour:	Nature
Front bezel material:	Aluminium

MOUNTING

Design:	raised
---------	--------

OPERATING-/INDICATION PART

Lever material:	plastic
Lever colour:	Black
Lever shape:	long

ELECTRICAL CHARACTERISTICS

Standards:	The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1
------------	---

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	≤2.5 Mio. cycles of operation
Switching angle:	42° left / 42° right
Switching action:	Momentary - Rest - Maintained
Weight:	0.037 kg
Switching positions:	3 positions

AMBIENT CONDITION

IP Protection:	IP65 front side
Operating temperature:	- 40 °C ... + 55 °C
Storage temperature:	- 40 °C ... + 85 °C


OTHER

Short Description: Actuator, Ø 29 mm, non illuminative, Black, long, Nature, Aluminium, anodised, Momentary - Rest - Maintained


Hints: Max. 3 switching elements can be clipped on

max. number of switching elements: 3

Switching positions:

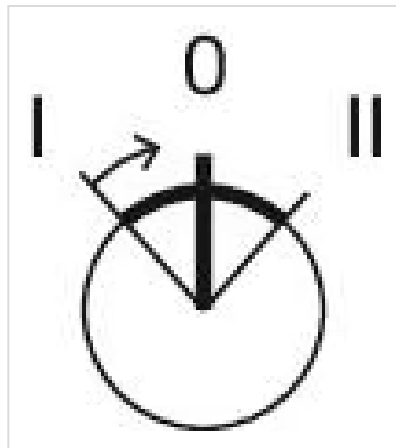


Dimension drawings:

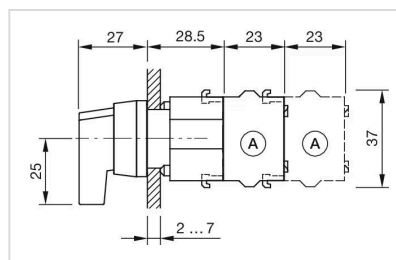

A = Screw terminal

Mounting cut-outs:

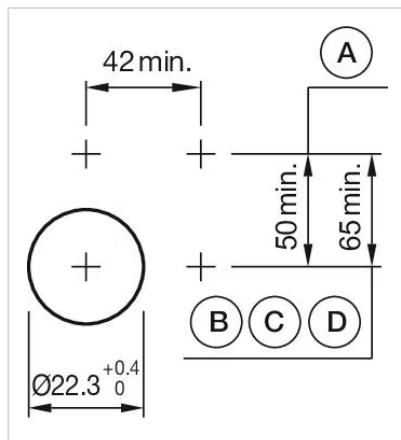

A = Screw terminal
 B = Push-in terminal (PIT)
 C = Plug-in terminal 6.3 mm x 0.8 mm
 D = Double plug-in terminal 6.3 mm x 0.8 mm

Wiring diagrams:

