


# Actuator

45-  
481.2810

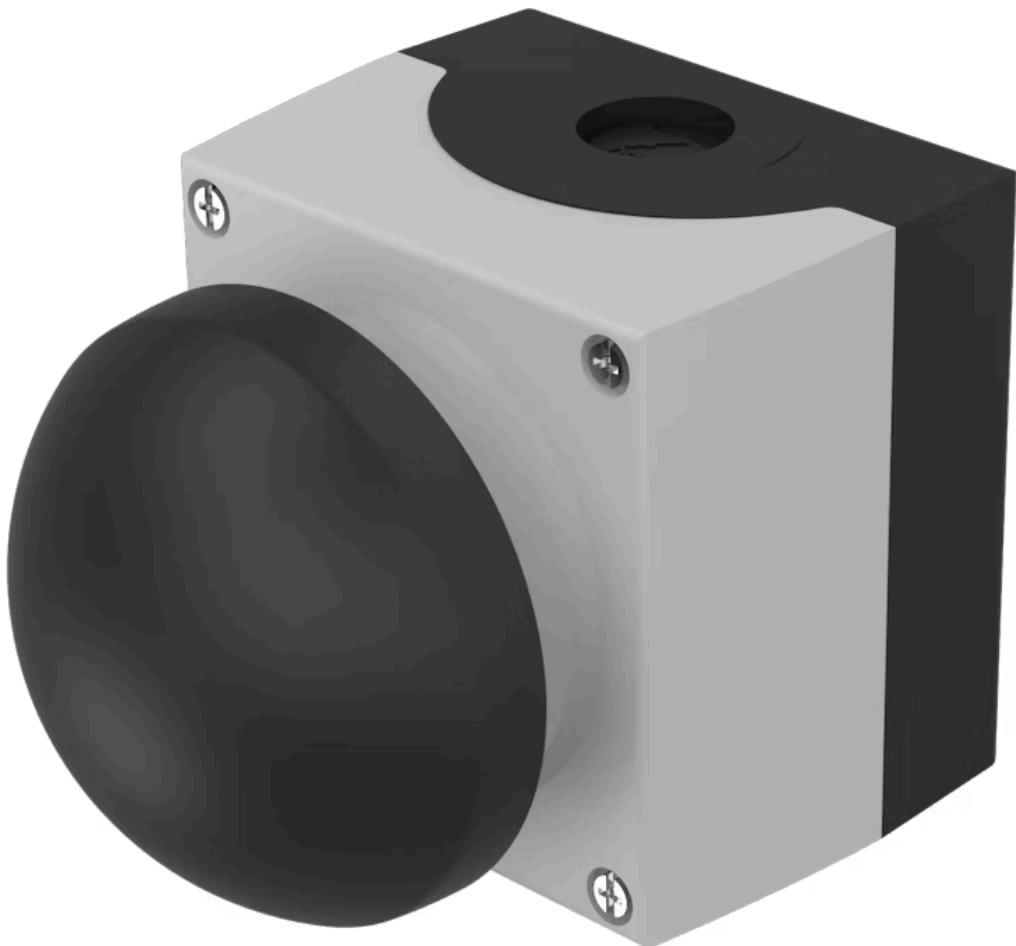

<https://eao.com/p/45-481.2810>

Your product:

---



## 45-481.2810 Actuator

### FRONT

**Front dimension:** 85 mm x 85 mm

### MOUNTING

**Design:** raised

**Component mounting type:** Base mounting

### OPERATING-/INDICATION PART

**Lens illumination:** non illuminative

**Lens colour:** Black

**Lens material:** Plastic

**Lens optics:** opaque

### ELECTRICAL CHARACTERISTICS

**Rated Operational Voltage Ue:** At AC: rated value 5 ... 500 V  
At DC: rated value 5 ... 500 V

### MECHANICAL CHARACTERISTIC

**Weight:** 0.642 kg

**Switching action:** Momentary

**Switching system:** Slow-make switching element

**Release type:** Pull unlock

### AMBIENT CONDITION

<b>IP front protection:</b>	IP66, IP67, IP69K
<b>Storage temperature:</b>	- 40 °C ... + 80 °C
<b>Climate resistance:</b>	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6, 3B2
<b>Vibration resistance:</b>	According to IEC 60068-2-6: 10 ... 500 Hz: 5 g
<b>Shock resistance:</b>	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

## OTHER

<b>Short Description:</b>	Actuator, 85 mm x 85 mm, non illuminative, Black, Plastic, opaque, Momentary, IP66, IP67, IP69K, Pull unlock
<b>Housing colour:</b>	Grey
<b>Housing material:</b>	Metal
<b>Dimension drawings:</b>	

