

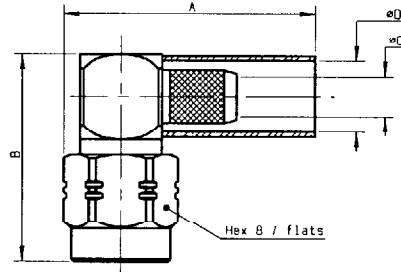
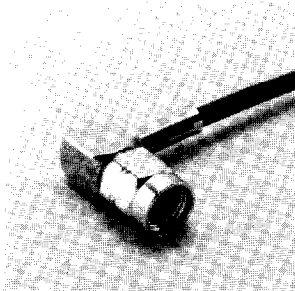


RIGHT ANGLE PLUG, CRIMP TYPE, FOR FLEXIBLE CABLE

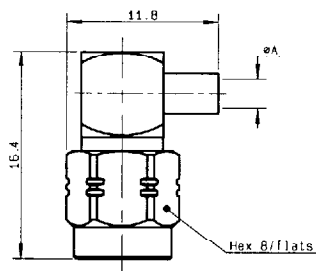

cable group	part number	A	B	C	D	mounting	finish	note
2.6/ 50 / S	R124 172 120	18	16,35	1,61	3,25	M 02	BBR	3 piece SMA
2.6/ 50 / S	R124 172 123	18	16,35	1,61	3,25	M 02	Gold	
2.6/ 50 / D	R124 174 120	18	16,35	1,61	3,5	M 02	BBR	
2.6/ 50 / D	R124 174 123	18	16,35	1,61	3,5	M 02	Gold	
5 / 50 / S	R124 175 120	21	16,35	3,1	5,41	M 02	BBR	3 piece SMA
5 / 50 / S	R124 175 123	21	16,35	3,1	5,41	M 02	Gold	
5 / 50 / D	R124 176 120	21	16,35	3,1	5,8	M 02	BBR	
5 / 50 / D	R124 176 123	21	16,35	3,1	5,8	M 02	Gold	
5.7/ 50 / D	R124 176 220●	21	16,8	3,87	6,6	M 02	BBR	3 piece SMA Cable TZC 50019

RIGHT ANGLE PLUG, SOLDER TYPE, FOR SEMI-RIGID CABLE

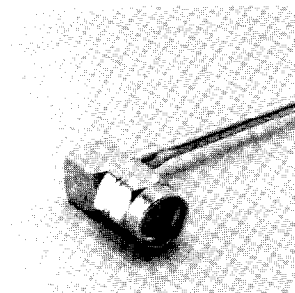

cable group	part number	A	mounting	finish
.085	R124 153 001	2,25	M 05	BBR
.085	R124 153 003	2,25	M 05	Gold
.141	R124 154 001	3,65	M 05	BBR
.141	R124 154 003	3,65	M 05	Gold

● Upon request.

Standard packaging : 100 pieces