


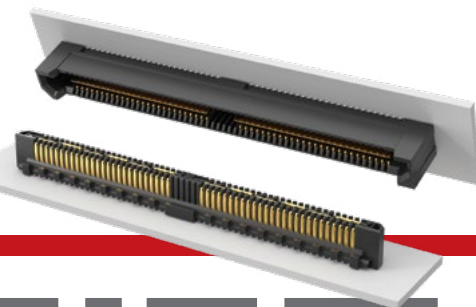

QRM8 Board Mates: QRF8

QRF8 Board Mates: QRM8

QRM8/QRF8 Cable Mates: EQRD

SPECIFICATIONS

Insulator Material:

Black LCP

QRM8 Terminal Material:

Phosphor Bronze

QRF8 Contact Material:

BeCu

Ground Plane Material:

Phosphor Bronze

Plating:

Au or Sn over
50 μ" (1.27 μm) Ni

Current Rating:

Contact:

2.2 A per pin (2 pins powered)

Ground Plane:

8.5 A per ground plane
(1 ground plane powered)

Operating Temp Range:

-55 °C to +125 °C


Voltage Rating:

215 VAC

Max Cycles:

100

QRM8	PINS PER ROW NO. OF PAIRS	LEAD STYLE	PLATING OPTION	TYPE	A	OTHER OPTIONS	"X"R
	-026, -052, -078 (52 total pins per bank = -D)	-02.0 = 2 mm Body Height Not available with -054 & -078 Positions)	-L = 10 μ" (0.25 μm) Gold on contact, Matte Tin on tail	-D = Single- Ended		-GP = Guide Post	Leave blank for Tray Packaging
	-018, -036, -054 (18 pairs per bank = -D-DP)	-05.0 = 5 mm Body Height	-S = 30 μ" (0.76 μm) Gold on contact, Matte Tin on tail	-D-DP = Differential Pair		-K = (5.00 mm) .197" DIA Polyimide Film Pick & Place Pad	-TR = Tape & Reel
		-07.0 = 7 mm Body Height					-FR = Full Reel Tape & Reel (must order maximum quantity per reel; contact Samtec for quantity breaks)

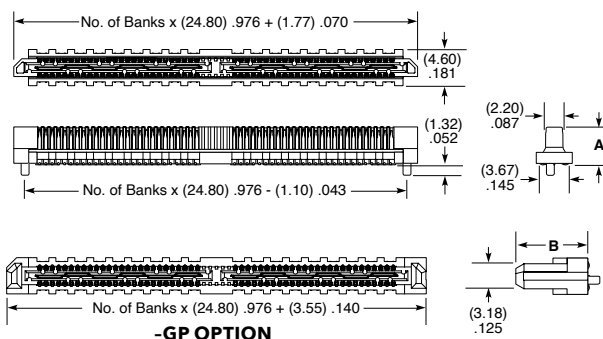

LEAD STYLE	A	B
-02	(4.81) .189	(6.12) .241
-05	(7.81) .307	(9.12) .359
-07	(9.78) .385	(11.12) .438

View complete specifications at: samtec.com?QRM8

PROCESSING

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0.10 mm) .004" max

(0.18 mm) .007" max

(0.15 mm) .006" max

(0.36-0.78)*

*(.004" stencil solution

may be available; contact

ipg@samtec.com)


Board Stacking:

For applications requiring

more than two connectors

contact ipg@samtec.com

QRF8	PINS PER ROW NO. OF PAIRS	LEAD STYLE	PLATING OPTION	TYPE	A	OTHER OPTIONS	"X"R
	-026, -052, -078 (52 total pins per bank = -D)	-05.0 = 5 mm Body Height	-L = 10 μ" (0.25 μm) Gold on contact, Matte Tin on tail	-D = Single- Ended		-GP = Guide Post	Leave blank for Tray Packaging
	-018, -036, -054 (18 pairs per bank = -D-DP)	-07.0 = 7 mm Body Height	-S = 30 μ" (0.76 μm) Gold on contact, Matte Tin on tail	-D-DP = Differential Pair		-K = (5.00 mm) .197" DIA Polyimide Film Pick & Place Pad	-TR = Tape & Reel (Not available with -054 & -078 positions)
							-FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks) (Not available with -054 & -078 positions)

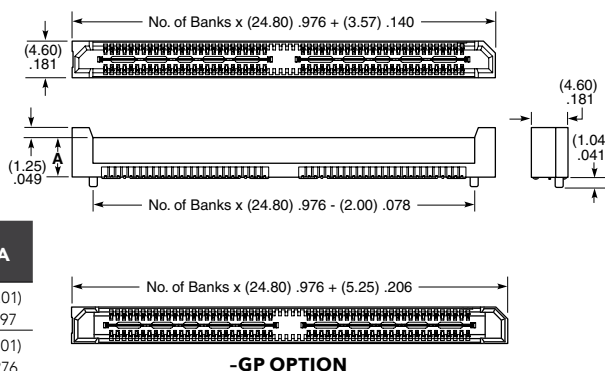


LEAD STYLE	A
-05	(5.01) .197
-07	(7.01) .276

MATED HEIGHT*			
QRF8 LEAD STYLE	QRM8 LEAD STYLE		
	-02.0	-05.0	-07.0
-05	(7.00) .276	(10.00) .394	(12.00) .472
-07	(9.00) .354	(12.00) .472	(14.00) .551

*Processing conditions will affect mated height.
See SO Series for board space tolerances.

View complete specifications at: samtec.com?QRF8

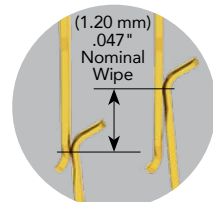

Note:
Some lengths, styles and
options are non-standard,
non-returnable.