


Large Incandescent Indicators

WITH LIGHT SHIELD LENS CAPS
FOR MOUNTING IN 1" CLEARANCE HOLE
FOR 24 TO 250V OPERATION

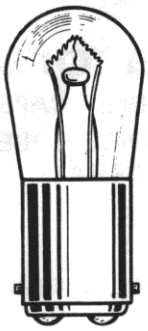


S-6
DOUBLE CONTACT
BAYONET BASE

See lamp ratings
on page K.

Recognized under the component
program of Underwriters'
Laboratories Inc.

75W., 125V.

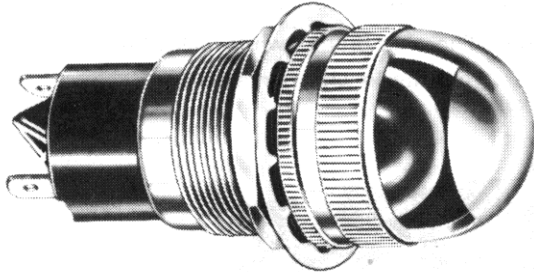

47-3402-2900-301

47 SERIES
49 SERIES
50 SERIES
151 SERIES

BASE PART NUMBERS

MATERIALS AND FINISHES:

- **Mounting Bushing:** Standard—brass, white nickel finish. Optional—black nickel finish.
- **Light Shield Cap:** Brass, polished chrome finish. Optional—black nickel finish.
- **Knurled Flange Ring:** Standard—brass, polished chrome finish. Optional—black nickel finish.
- **Internal-tooth Lockwasher:** Phosphor bronze, white nickel finish.
- **Terminals:** Solder — brass, hot tinned. Screws—brass, white nickel finish.
- **Quick Connect—**brass, tinned. Mate with standard female receptacles.
- **Mounting Nut:** Brass, white nickel finish.

WITH SCREW-ON LENS CAPS

fixed solder	fixed screw	quick connect
1/16 PANEL (REF.) 3/32 X 1 9/64 O.D. FLANGE .025 ± .005 X 1 3/8 ± .020 O.D. INTERNAL TOOTH LOCKWASHER 1/8 X 1 1/8 ACROSS FLATS HEX. NUT. 1-27 NS THD. MOUNTING BUSHING. 2 HOLES 3/32 DIA. PROJECTION BACK OF PANEL 1-11/16 MAX.	6-32 NC THD.	
47-3402-29-301	47-3202-29-301	47-6602-29-301

CAP PART NUMBERS	COMPLETE ASSEMBLY PART NUMBERS		
21/32 1-9/64 3/8 1-1/16 MAX. 1-27 NS THD. (INTERNAL) DOME 47-2900-300 one opening, 3/8"x1"	47-3402-2900-301	47-3202-2900-301	47-6602-2900-301
21/32 1-9/64 1/4 1-1/16 MAX. 1-27 NS THD. (INTERNAL) DOME 49-2900-300 one opening, 1/4"x1"	49-3402-2900-301	49-3202-2900-301	49-6602-2900-301
21/32 1-9/64 1/8 1-1/16 MAX. 1-27 NS THD. (INTERNAL) DOME 50-2900-300 one opening, 1/8"x1"	50-3402-2900-301	50-3202-2900-301	50-6602-2900-301
23/32 1-9/64 9/16 1-1/16 MAX. 1-27 NS THD. (INTERNAL) DOME 151-2900-300 one opening, 9/16"x1"	151-3402-2900-301	151-3202-2900-301	151-6602-2900-301

Part numbers shown in gray are normally
in inventory at your Dialight Distributor.