

supplied in strips of 24. Simply snap off the desired number of positions required and insert into PC board. The modular terminal block can be plugged into the header strip at anytime.

- Accepts #22-16 AWG wire
- Because of accumulating tolerances, we recommend a maximum of 24 positions per row
- Header strips and terminal blocks sold separately

 
MATERIAL:

ELECTRICAL:

MECHANICAL:

Operating Temp:
22°F to 248°F (-30°C to 120°C)
Peak Temp: +393°F (+200°C)


- Use header strip to connect to PCB



3.5mm SPACING			
CAT. NO.	POSITIONS	A DIM.	CURRENT RATING
8722	2	.276 (7.0)	6 Amps
8723	3	.413 (10.5)	

CAT. NO. 8724

- Use header strip to connect to PCB

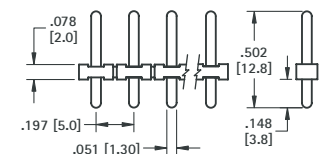

Recommended Mtg. Hole Size: .059 (1.50)

5mm SPACING			
CAT. NO.	POSITIONS	A DIM.	CURRENT RATING
8725	2	.394 (10.0)	10 Amps
8726	3	.591 (15.0)	

CAT. NO. 8727

NOTES

[illegible]