


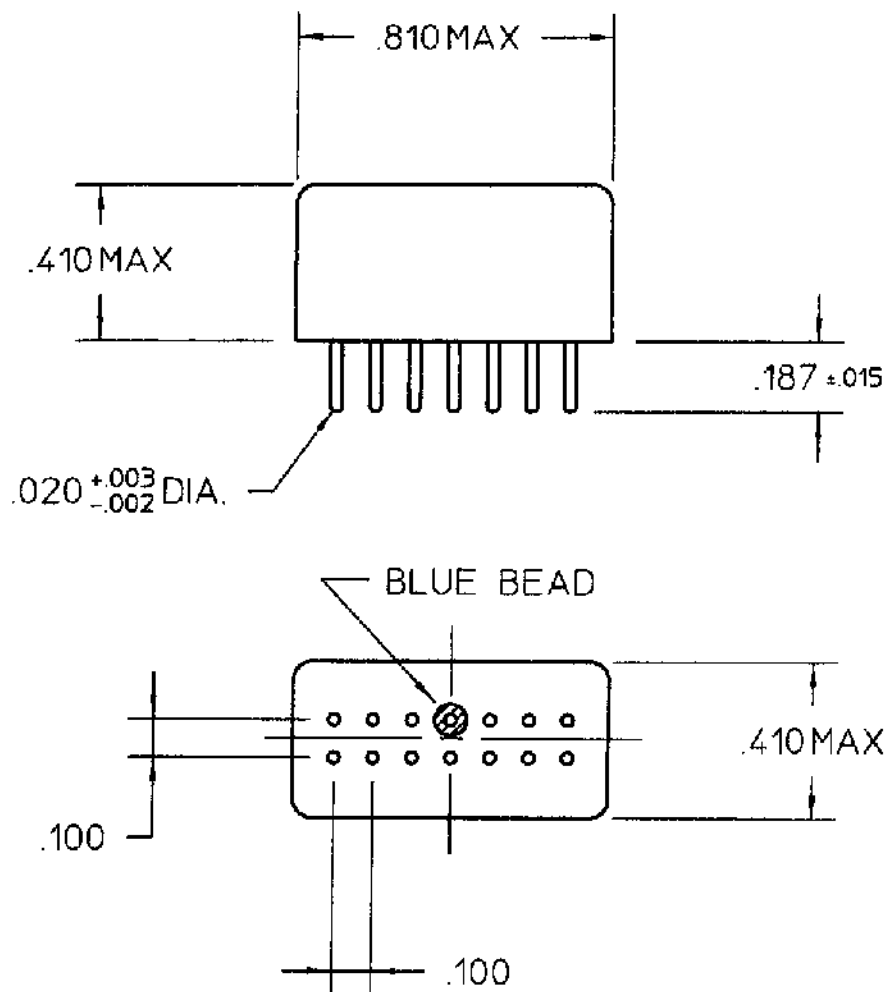

REV. 7
DCO 63333

COIL: @ 25°C
 RESISTANCE _____ 100 OHMS $\pm$ 10%
 NOMINAL VOLTAGE _____ 12.0 VDC
 MUST OPERATE _____ 6.5 VDC
 MUST RELEASE _____ 10.1 VDC MAX, 0.92 VDC MIN

ENVIRONMENT:


VIBRATION _____ 10 _____ CPS TO _____ 2000 _____ CPS @ _____ 15 _____ g's
 SHOCK _____ 100 _____ g's _____ 6 _____ MS. DURATION
 TEMPERATURE _____ -65 _____ °C TO _____ +125 _____ °C

NOTES: (LEVEL 1 ACCEPTANCE TESTING ONLY)

OPERATE & RELEASE 7 MS MAX.

(INCLUDING BOUNCE)

CUSTOMER DATA SHEET

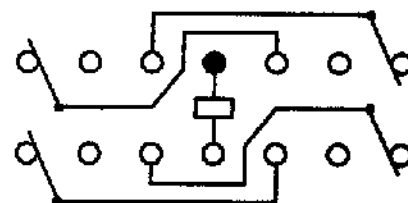

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
 2 AMP 28 VDC RESISTIVE

DR. R.B. 10/16/90

CKT/G 10-24-00

CI Technologies
 advanced control electronic solutions

CUST. _____ OPL
 CUST. NO. M39016/40-010 REV. _____

"SR" RELAY

SR-7610