

SUMMARY

Wires

High voltage	1
--------------	---



Image is for illustrative purpose only

Series	3Y
Termination type	Female solder High-Voltage
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	5.70 - 7.20 mm
Status	active
Matching parts	ERA.3Y.430.CLA

Download

[Request a quote](#)

[Eplan](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FFA*: Straight plug with cable collet
Keying	Circular
Housing Material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Weight	225.18 g

Performance

Configuration	3Y.430 : 1 High Voltage
Insulator	T: PTFE
Rated Current	15 Amps

Specifications


Contact Type: Solder	
Test voltage (kV DC)(value for male contact plug mated with female contact socket)	42
Test voltage (kV AC)	29
Creepage distance min.:	58 mm

Others

Salt Spray Corrosion:	>1000 hr
-----------------------	----------

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

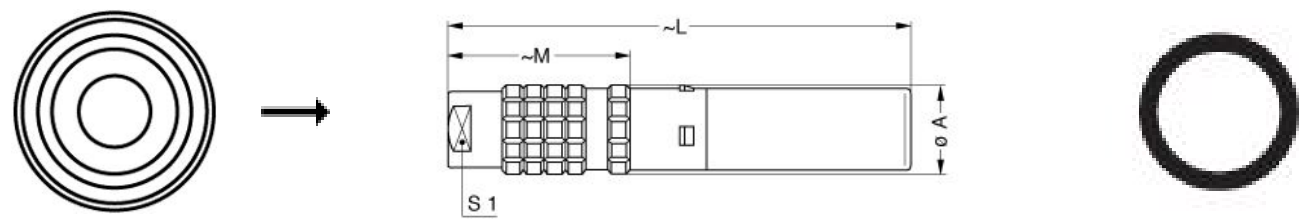

Dimensions

	A	L	M	S1
mm.	19	200	105	15
in.	0,75	7,87	4,13	0,59

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.