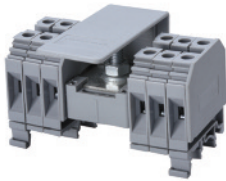
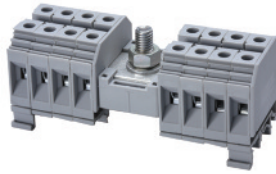
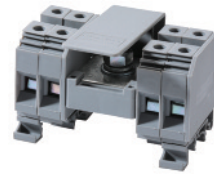


CDB6/x*

CDB10/x*

CDB25/x*


8 mm

43 x 47 mm

12 mm

Polyamide 6.6

1 Lug/ M6 bolt connection for ring lug
Screw clamp connection

10-2 AWG
22-8 AWG

600 V

100 A
50 A

35 lb-in
14 lb-in

10 mm

43 x 47 mm

12 mm

Polyamide 6.6

1 Lug/ M8 bolt connection for ring lug
Screw clamp connection

8-1/0 AWG
22-6 AWG

600 V

130 A
65 A

53 lb-in
14 lb-in

12 mm

56 x 49 mm

18 mm

Polyamide 6.6

1 Lug/ M8 bolt connection for ring lug
Screw clamp connection

6-2/0 AWG
12-2 AWG

600 V

150 A
75 A

53 lb-in
22 lb-in

 

Cat. No.	H x W x L (mm)	Outputs	Std. Pk.	Cat. No.	H x W x L (mm)	Outputs	Std. Pk.	Cat. No.	H x W x L (mm)	Outputs	Std. Pk.
CDB6/2	43 x 47 x 64	8	10	CDB10/2	43 x 47 x 72	8	10	CDB25/2	56 x 49 x 88	8	10
CDB6/3	43 x 47 x 80	12	10	CDB10/3	43 x 47 x 92	12	10	CDB25/3	56 x 49 x 112	12	10
CDB6/4	43 x 47 x 96	16	5	CDB10/4	43 x 47 x 112	16	5	CDB25/4	56 x 49 x 136	16	5

Cat. No. Std. Pk.


CA702
CA802

 
50
50

Cat. No. Std. Pk.


CA702
CA802

50
50

Cat. No. Std. Pk.


CA702
CA802

50
50

MT8 100

MT10 100

MT12 100

SWL6 100

* NOTE:
x signifies how many blocks are on each
side of input.