


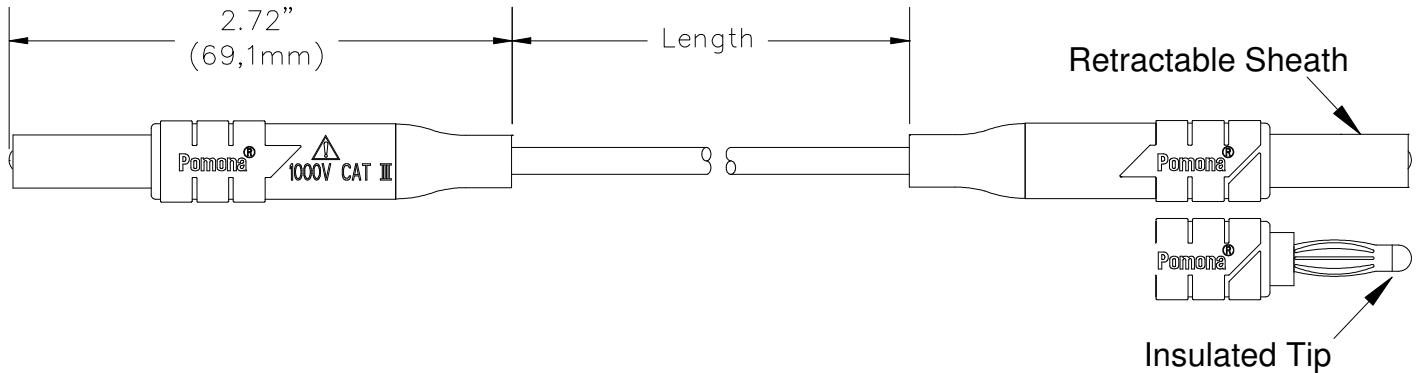

MATERIALS:

Retractable Sheath Banana Plug:

Plug Body: Gold Plated Tellurium Copper

Banana Spring: Gold Plated Beryllium Copper

Compression Spring: Stainless Steel

Tip: Polypropylene, Color Matches Color of Wire

Insulation: Polypropylene, Molded to the Plug and Wire. Color Matches Color of Wire.

Wire: 12 AWG, Stranding 10 x 26/36 Bare Copper, PVC Insulated, .144" (3,66mm) O.D.

RATINGS:

Operating Temperature: +131° F (+55° C) Max

Operating Voltage: 1000V Category III, IEC1010-2-031

Current: 7 Amperes

ORDERING INFORMATION:

Model 5291A-**Length-Color**

Length = 36" (91.44cm) & 60" (152.4cm)

Color = -0 (Black), -2 (Red)

Ordering Example: 5291A-36-2 Patch Cord is in 36" and Red