

# Actuator

45-  
2631.29H0.000



<https://eao.com/p/45-2631.29H0.000>

Your product:

---



## 45-2631.29H0.000 Actuator

### FRONT

Front dimension:	Ø 40 mm
Front bezel colour:	Silver
Front bezel material:	Metal

### MOUNTING

Design:	raised
---------	--------

### OPERATING-/INDICATION PART

Lens illumination:	illuminative
Lens colour:	Green
Lens shape:	mushroom-head
Lens material:	Plastic
Lens optics:	transparent

### MECHANICAL CHARACTERISTIC


Weight:	0.053 kg
Switching action:	Momentary
Switching system:	Slow-make switching element
Mechanical lifetime:	10 Mio. cycles of operation
Operating frequency:	Max. 3 600/h

### AMBIENT CONDITION


<b>Vibration resistance:</b>	According to IEC 60068-2-6: 20 ... 500 Hz: 5 g
<b>IP front protection:</b>	IP66, IP67, IP69K
<b>Operating temperature:</b>	– 25 °C ... + 70 °C
<b>Storage temperature:</b>	– 40 °C ... + 80 °C
<b>Climate resistance:</b>	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6
<b>Shock resistance:</b>	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

## OTHER

<b>Housing colour:</b>	Silver
<b>Housing material:</b>	Metal
<b>Short Description:</b>	Actuator, Ø 40 mm, mushroom-head, illuminative, Green, Plastic, transparent, Silver, Metal, Momentary, IP66, IP67, IP69K
<b>Wiring diagrams:</b>	

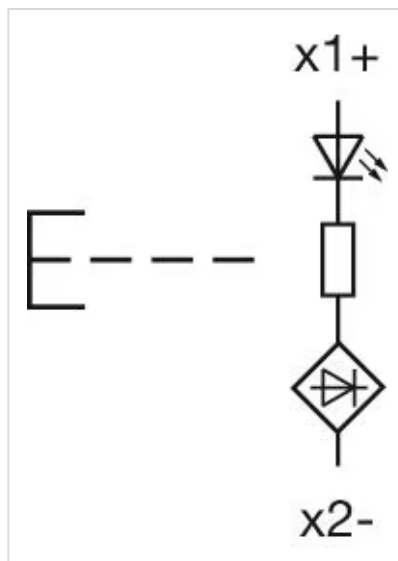

**Dimension drawings:**

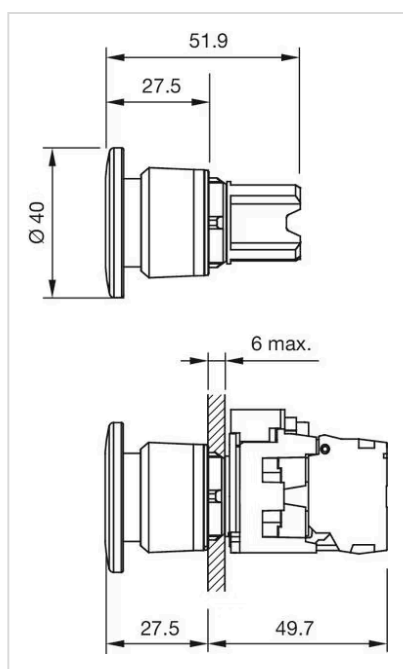

#### Mounting cut-outs:

