



GC Series



FF

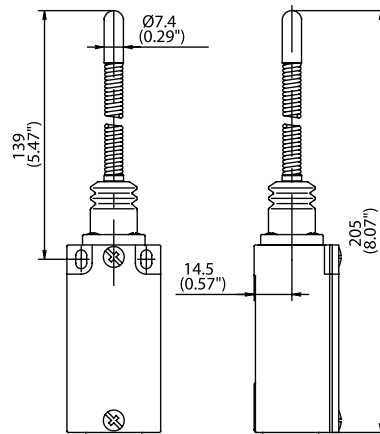

AF

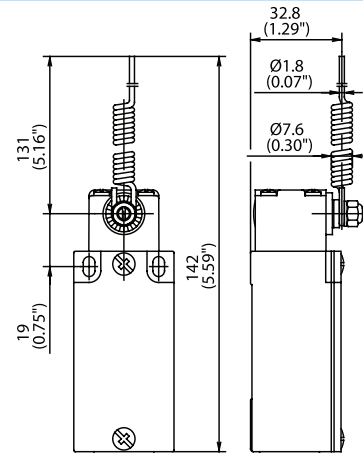


Switching Operation

1 NC / 1 NO Contacts


Slow Action

 602.1140.476
GC-U1 FF




Snap Action

 602.1190.100
GC-SU1 FF




Slow Action

 602.1139.106
GC-U1 AF



Snap Action

 602.1189.128
GC-SU1 AF



2 NC Contacts

-

-

-

-

2 NO Contacts

-

-

-

-

1 NC / 1 NO Contacts Overlapping

-

-

-

-

Replacement actuator:

391.2400.510

391.2390.725

Technical Information

Slow Action

Snap Action

Maximum Switching Voltage

240V

240V

Max. Switching Amps (up to)*

10A

10A

B10d (up to)*

20 Million

20 Million

Mechanical Service Life (up to)*

10 x 10⁶

10 x 10⁶

Switching Frequency

≤ 100/min

≤ 100/min

Operating Temperature

-30 °C to +80 °C

-30 °C to +80 °C

Protection Rating

IP65

IP65

Utilization Category (up to)*

AC-15, Ue/Ue 240V 3A

AC-15, Ue/Ue 240V 3A

Rate Insulation Voltage

400VAC

400VAC

Approvals



* Depending on switching system - see technical information for details

Special features/variants (on request)

- Different spring lengths
- Different spring versions or spring rod

Special features/variants (on request)

- Available with various actuator lengths and actuator directions

Drawing dimensions in mm