

Actuator

45-

2234.4FJ0.000

<https://eao.com/p/45-2234.4FJ0.000>

Your product:



45-2234.4FJ0.000
Actuator

FRONT

| | |
|------------------------------|-----------|
| Front dimension: | Ø 38 mm |
| Front bezel colour: | Sand grey |
| Front bezel material: | Metal |

MOUNTING

| | |
|----------------|-------|
| Design: | flush |
|----------------|-------|

OPERATING-/INDICATION PART

| | |
|-----------------------------|--------------|
| Lens illumination: | illuminative |
| Lens colour: | Blue |
| Lens shape: | flush |
| Lens material: | Plastic |
| Lens optics: | transparent |
| Illumination colour: | Blue |

MECHANICAL CHARATERISTIC

| | |
|-----------------------------|-----------------------------|
| Weight: | 0.09 kg |
| Switching action: | Maintained |
| Switching system: | Slow-make switching element |
| Mechanical lifetime: | 500 000 cycles of operation |
| Operating frequency: | Max. 1 800/h |


AMBIENT CONDITION

| | |
|-------------------------------|--|
| IP front protection: | IP66, IP67, IP69K |
| Operating temperature: | – 25 °C ... + 70 °C |
| Storage temperature: | – 40 °C ... + 80 °C |
| Vibration resistance: | According to IEC 60068-2-6: 20 ... 500 Hz: 5 g |
| Shock resistance: | According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms |
| Climate resistance: | During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6 |

OTHER

| | |
|---------------------------|---|
| Housing colour: | Silver |
| Housing material: | Metal |
| Hints: | Push to unlatch |
| Short Description: | Actuator, Ø 38 mm, flush, illuminative, Blue, Plastic, transparent, Sand grey, Metal, Maintained, IP66, IP67, IP69K, Blue |

Dimension drawings:

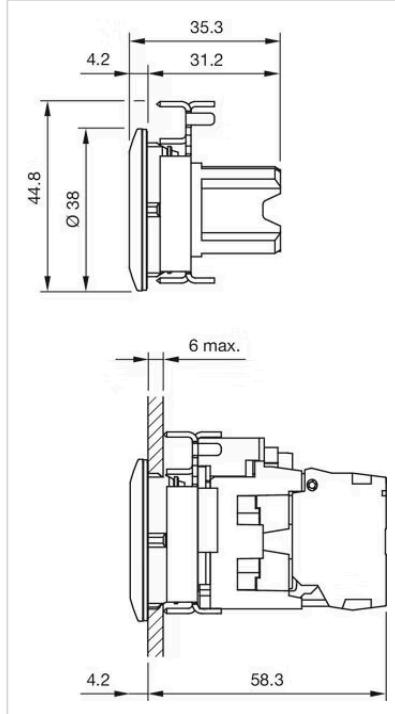

Wiring diagrams:

