
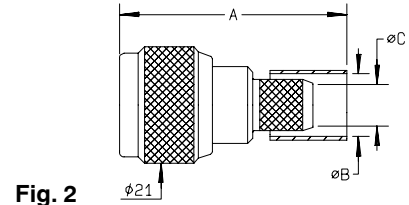
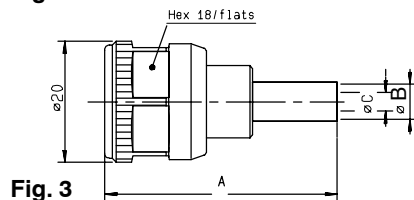




## STRAIGHT PLUGS, FULL CRIMP TYPE, FOR FLEXIBLE CABLES (single piece body)

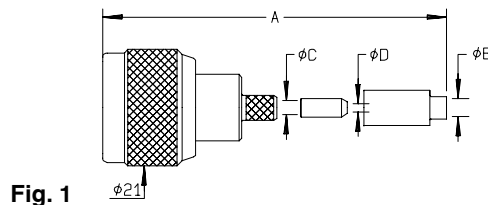

| cable group    | part number  | fig. | dimensions (mm) |       |       |      | captured center contact | mounting | note                                       |
|----------------|--------------|------|-----------------|-------|-------|------|-------------------------|----------|--------------------------------------------|
|                |              |      | A               | B     | C     | D    |                         |          |                                            |
| 2 / 50 / S + D | R161 071 000 | 1    | 39.7            | 2.35  | 3.38  | 1    | YES                     | M09      |                                            |
| 2.6 / 50 / S+D | R161 072 000 | 1    | 39.7            | 3.25  | 3.38  | 1.63 | YES                     | M09      |                                            |
| 5 / 50 / S     | R161 082 000 | 2    | 38.5            | 5.41  | 3.11  |      | YES                     | M12      | LMR 200 cable                              |
| 5 / 50 / S     | R161 082 200 |      |                 |       |       |      |                         |          |                                            |
| 5 / 50 / D     | R161 083 000 | 2    | 38.5            | 5.8   | 3.11  |      | YES                     | M12      |                                            |
| 5 / 50 / D     | R161 083 137 | 3    | 38.5            | 5.8   | 3.11  |      | YES                     | M24      | For intermodulation application / tool*    |
| 10 / 50 / S    | R161 075 000 | 2    | 40.2            | 11.05 | 7.46  |      | YES                     | M10      |                                            |
| 10.3 / 50 / S  | R161 075 060 | 2    | 40.2            | 11.05 | 7.46  |      | YES                     | M10      | LMR 400 cable                              |
| 10.3 / 50 / D  | R161 076 000 | 2    | 40.2            | 11.4  | 6.4   |      | YES                     | M10      | ETHERNET cable                             |
| 11 / 50 / D    | R161 088 000 | 2    | 40.2            | 11.4  | 7.46  |      | YES                     | M10      | For intermodulation application / tool*    |
| 11 / 50 / D    | R161 088 137 | 3    |                 |       |       |      |                         | M24      |                                            |
| 15.2 / 50 / S  | R161 079 220 | 2    | 49              | 15.87 | 11.96 |      | YES                     | M11      | LMR 600 cable / solder type center contact |

\* Torque wrench : R282 303 020 (page 58)

## STRAIGHT PLUGS, CLAMP TYPE, FOR FLEXIBLE CABLES

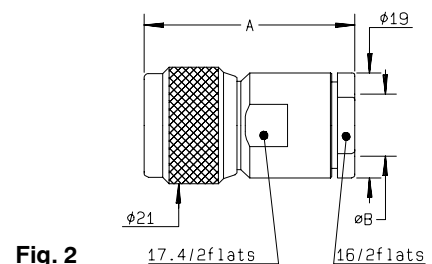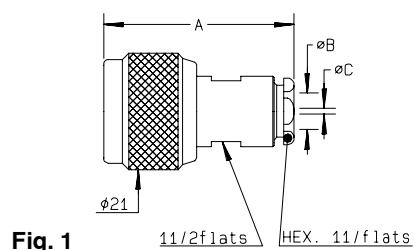

| cable group          | part number  | fig. | dimensions (mm) |      |     | captured center contact | mounting |
|----------------------|--------------|------|-----------------|------|-----|-------------------------|----------|
|                      |              |      | A               | B    | C   |                         |          |
| 2.6 / 50 / S + D     | R161 004 000 | 1    | 33.9            | 3.1  | 1.7 | YES                     | M01      |
| 5 / 50 / S + D       | R161 006 000 | 1    | 34.4            | 5.6  |     | NO                      | M02      |
| 5 / 50 / S + D       | R161 010 000 | 1    | 34.9            | 5.6  |     | YES                     | M03      |
| 10 + 11 / 50 / S + D | R161 020 000 | 2    | 38.1            | 11.2 |     | NO                      | M04      |
| 10 + 11 / 50 / S + D | R161 022 000 | 2    | 38.9            | 11.2 |     | YES                     | M05      |

Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.

### STRAIGHT PLUGS, EZ FIT TYPE, FOR CORRUGATED CABLES

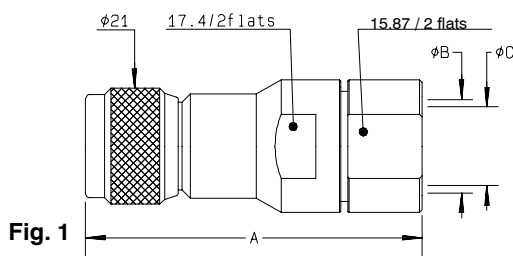


Fig. 1

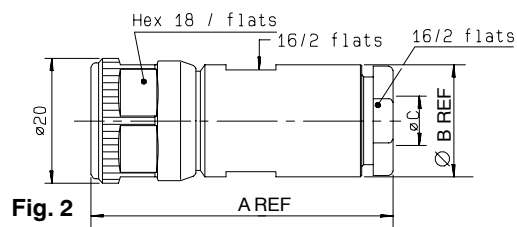


Fig. 2

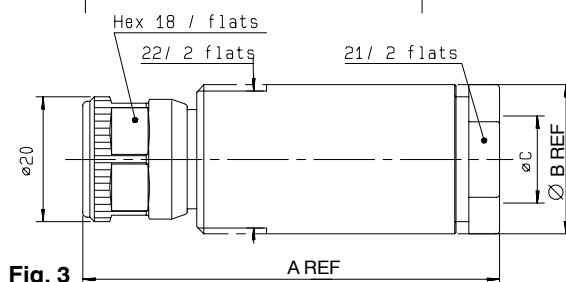


Fig. 3

| cable group                   | part number          | fig.      | dimensions (mm) |    |     | captured center contact | mounting |
|-------------------------------|----------------------|-----------|-----------------|----|-----|-------------------------|----------|
|                               |                      |           | A               | B  | C   |                         |          |
| 1/4" superflexible corrugated | <b>R161 036 007</b>  | 2         | 52.3            | 18 | 7.9 | YES                     | M22      |
| 3/8" superflexible corrugated | <b>R161 036 207</b>  | 3         | 65              | 24 | 11  | YES                     | M22      |
| 1/2" flexible corrugated      | <b>R161 091 020W</b> | not shown |                 |    |     | YES                     |          |
| 1/2" superflexible corrugated | <b>R161 037 020</b>  | 3         | 65              | 24 | 14  | YES                     | M22      |
| 7/8" flexible corrugated      | <b>R161 033 020W</b> | not shown |                 |    |     | YES                     |          |

\* Torque wrench : R282 303 020 (page 58)

### STRAIGHT PLUGS, FOR SEMI RIGID CABLES

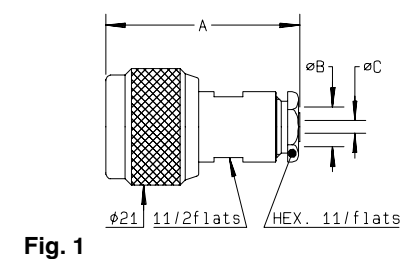


Fig. 1

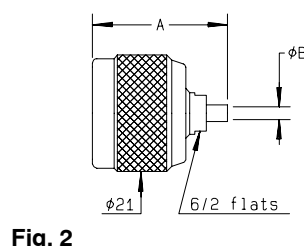


Fig. 2

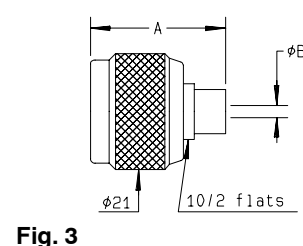


Fig. 3

| cable group | part number          | fig. | dimensions (mm) |      |      | captured center contact | mounting | note        |
|-------------|----------------------|------|-----------------|------|------|-------------------------|----------|-------------|
|             |                      |      | A               | B    | C    |                         |          |             |
| .085"       | <b>R161 050 000</b>  | 1    | 35              | 5.6  | 2.25 | NO                      | M06      | Clamp type  |
| .085"       | <b>R161 050 020●</b> | 1    | 35              | 5.6  | 2.25 | YES                     | M06      | Clamp type  |
| .085"       | <b>R161 050 300</b>  | 2    | 24.4            | 2.25 |      | NO                      | M07      | Solder type |
| .141"       | <b>R161 051 000</b>  | 2    | 24.4            | 3.65 |      | NO                      | M07      | Solder type |
| .141"       | <b>R161 052 000</b>  | 1    | 35              | 5.6  | 3.65 | NO                      | M06      | Clamp type  |
| .141"       | <b>R161 052 020●</b> | 1    | 35              | 5.6  | 3.65 | YES                     | M06      | Clamp type  |
| .250"       | <b>R161 053 000</b>  | 1    | 35.4            | 6.6  |      | NO                      | M08      | Clamp type  |
| .250"       | <b>R161 053 020●</b> | 1    | 35.4            | 6.6  |      | YES                     | M08      | Clamp type  |
| .250"       | <b>R161 054 000</b>  | 3    | 24.4            | 6.45 |      | NO                      | M07      | Solder type |

● Upon request

Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.