
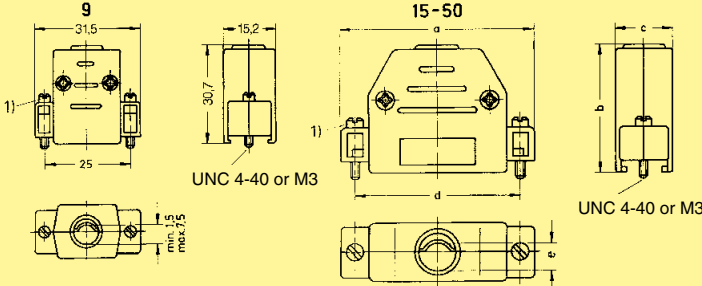
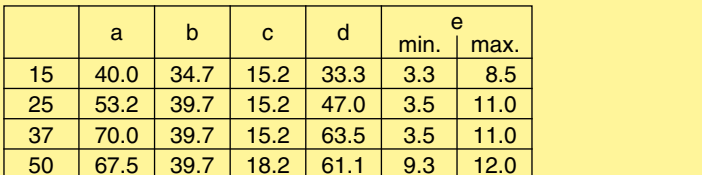
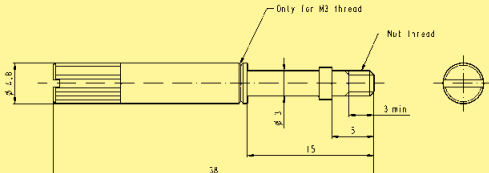
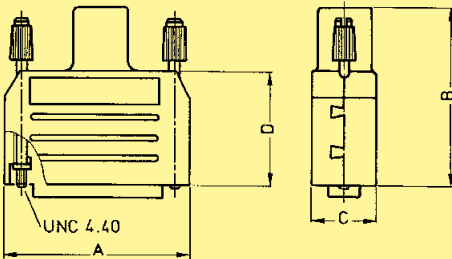
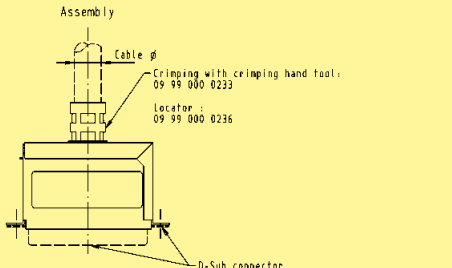


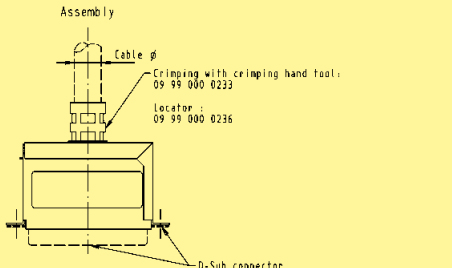

Top entry hoods with knurled or locking screws

Identification	No. of contacts	Part No.	Drawing	Dimensions in mm																									
Hood³⁾ Black thermoplastic with short locking screws	9 15 25 37 50	09 67 009 0442 09 67 015 0442 09 67 025 0442 09 67 037 0442 09 67 050 0442																											
Hood³⁾ Metallized thermo- plastic with short locking screws	9 15 25 37 50	09 67 009 04 . 3 09 67 015 04 . 3 09 67 025 04 . 3 09 67 037 04 . 3 09 67 050 04 . 3																											
Please insert digit for screw option Thread 4-40 UNC ▶ 4 Thread M3 ▶ 2																													
Knurled screw for metallized hood Thread UNC Thread M3	9-50 9-50	09 67 000 9925 ²⁾ 09 67 000 9930 ²⁾																											
Screened hood Order cover and internal metal screen separately				<table><tr><td></td><td>A</td><td>B</td><td>C</td><td>D</td></tr><tr><td>9</td><td>35.0</td><td>54</td><td>19.1</td><td>34</td></tr><tr><td>15</td><td>43.0</td><td>54</td><td>19.1</td><td>34</td></tr><tr><td>25</td><td>57.5</td><td>54</td><td>19.1</td><td>34</td></tr><tr><td>37</td><td>74.0</td><td>54</td><td>19.1</td><td>34</td></tr></table>		A	B	C	D	9	35.0	54	19.1	34	15	43.0	54	19.1	34	25	57.5	54	19.1	34	37	74.0	54	19.1	34
	A	B	C	D																									
9	35.0	54	19.1	34																									
15	43.0	54	19.1	34																									
25	57.5	54	19.1	34																									
37	74.0	54	19.1	34																									
Cover⁴⁾ Black thermoplastic with knurled screws	9 15 25 37	09 67 009 0422 09 67 015 0422 09 67 025 0422 09 67 037 0422		<table><tr><td></td><td colspan="2">Cable Ø (mm)</td></tr><tr><td></td><td>min.</td><td>max.</td></tr><tr><td>9</td><td>6.1</td><td>8.8</td></tr><tr><td>15</td><td>6.1</td><td>8.8</td></tr><tr><td>25</td><td>8.0</td><td>10.3</td></tr><tr><td>37</td><td>9.5</td><td>11.5</td></tr></table>		Cable Ø (mm)			min.	max.	9	6.1	8.8	15	6.1	8.8	25	8.0	10.3	37	9.5	11.5							
	Cable Ø (mm)																												
	min.	max.																											
9	6.1	8.8																											
15	6.1	8.8																											
25	8.0	10.3																											
37	9.5	11.5																											
Internal metal screen⁴⁾ metallized (Crimp tool see chapter 20)	9 15 25 37	09 67 009 0421 09 67 015 0421 09 67 025 0421 09 67 037 0421																											

1) Use of knurled screws is possible. Please order separately

2) Order 2 for each hood

3) Operating temperature: -20 °C ... +90 °C

4) Operating temperature: -55 °C ... +110 °C