


Actuator

704.101.01

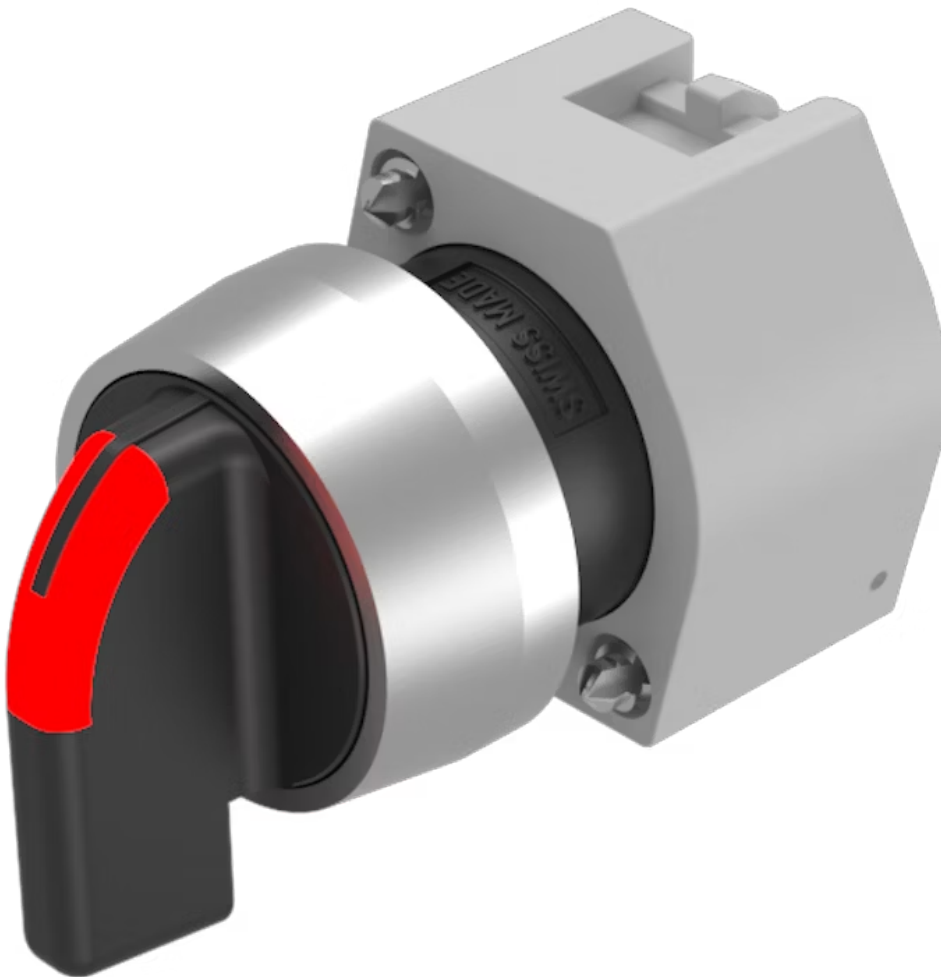

<https://eao.com/p/704.101.01>

Your product:



704.101.01 Actuator

FRONT

Front bezel colour:	Nature
Front bezel material:	Aluminium
Front dimension:	Ø 29 mm

MOUNTING

Design:	raised
---------	--------

OPERATING-/INDICATION PART

Lever material:	plastic
Lever shape:	long
Lever colour:	Black

ELECTRICAL CHARACTERISTICS

Standards:	The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1
------------	---

MECHANICAL CHARACTERISTIC

Weight:	0.037 kg
Mechanical lifetime:	≤2.5 Mio. cycles of operation
Switching positions:	2 positions
Switching angle:	90° right
Switching action:	Rest - Maintained

AMBIENT CONDITION

Storage temperature: - 40 °C ... + 85 °C

IP Protection: IP65 front side


OTHER

Hints: Max. 3 switching elements can be clipped on


Short Description: Actuator, Ø 29 mm, optional illuminative, Black, long, Nature, Aluminium, anodised, Rest - Maintained

max. number of switching elements: 3


Wiring diagrams:

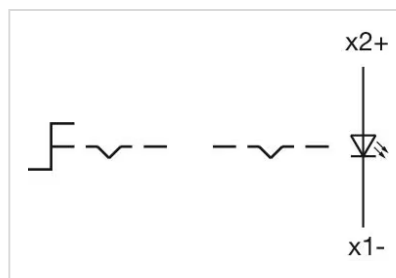

Switching positions:

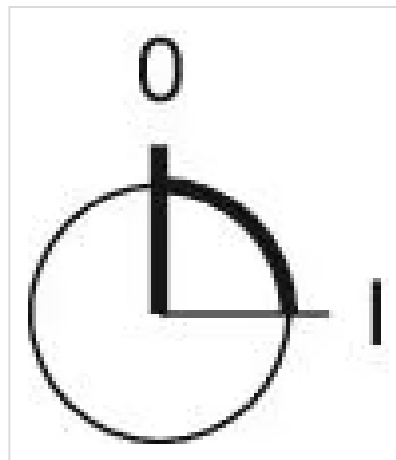


Dimension drawings:

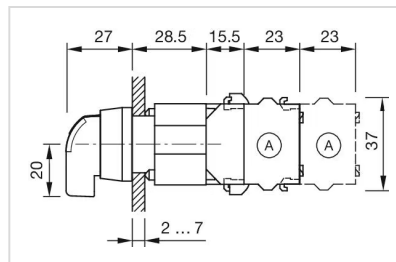

A = Screw terminal

Mounting cut-outs:

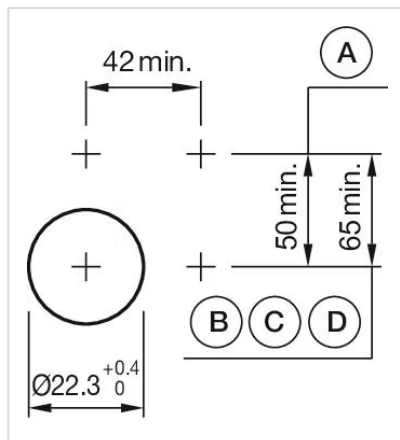

- A = Screw terminal
- B = Push-in terminal (PIT)
- C = Plug-in terminal 6.3 mm x 0.8 mm
- D = Double plug-in terminal 6.3 mm x 0.8 mm