




IN-SERIES ADAPTERS

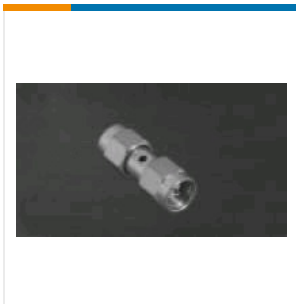

✓ Active

↓ **PRODUCT DRAWING**
English

TE CONNECTIVITY (TE)
2781 0000 02
[AMP](#) | [SAM](#) , [SMA](#)

1056336-1
TE Internal Number: 1056336-1
Alias ID: 2781-0000-02

[Always EU RoHS/ELV Compliant](#)

RF Connector Type **SMA**

50 Ohm **Yes**

75 Ohm **No**

Body Style **Straight**

Center Contact Material **Beryllium Copper**

Product Drawings

[OSM HIGH FREQUENCY \(27GHz\) PLUG TO PLUG ADAPTER](#)

PDF ([TIFF AVAILABLE](#))
English

[OSM HIGH FREQUENCY \(27GHz\) PLUG TO PLUG ADAPTER](#)

PDF ([TIFF AVAILABLE](#))
English

Product Specifications

Product Specification

[SMA In-Series Adapters](#)

PDF
English

Qualification Test Report

[SMA In-Line Adapters](#)

PDF
English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

RF Connector Type

SMA

Isolated Ground

No

Dielectric Material

TFE Fluorocarbon

Retractable Collar

Without

Product Type

Adapter

Configuration Features

Snap-Lock

Without

Electrical Characteristics

50 Ohm

Yes

75 Ohm

No

	Impedance (Ω)	50
Signal Characteristics	Frequency (GHz)	27
Body Features	Body Style	Straight
	Body Plating Finish	Passivated
	Gasket Material	Silicone Rubber
	Body Insulation	Without
	Body Material	Stainless Steel
Contact Features	Center Contact Material	Beryllium Copper
	Center Contact Plating Material	Gold
	Center Contact	With
Mechanical Attachment	Coupling Nut Material	Stainless Steel
	Safety Wire Holes	Without
	Coupling Nut Plating Finish	Passivated
Dimensions	Length	.878 mm [22.3 in]
Packaging Features	Packaging Method	Bag
Product Compliance	<div>Statement of Compliance</div> <div>PDF</div> <div>VIEW ALL PRODUCT COMPLIANCE</div>	