

RJ45 Plug Stewart

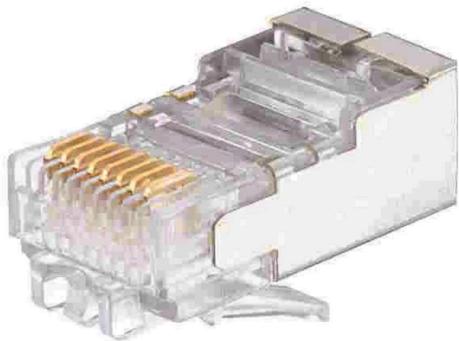


Image is for illustration purposes only. Please refer to product description.

Part number	09 12 000 9957
Specification	RJ45 Plug Stewart
HARTING eCatalogue	https://b2b.harting.com/09120009957

Identification

Category	Inserts
Element	Data connectors
Specification	for Han® RJ45 module

Version

Gender	Male
Number of contacts	8

Technical characteristics

Conductor cross-section [AWG]	AWG 24 ... AWG 22
Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained

Material properties

REACH SVHC substances	Not contained
-----------------------	---------------

Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
Approvals	DNV GL

Commercial data

Packaging size	10
Net weight	3 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140016385
ETIM	EC000438
eCl@ss	27440218 Module for industrial connectors (data)