

Receptacle Crimp**Specifications :**Contact Resistance : 20 m Ω MaxInsulator Resistance : 1000 M Ω Min at 500V DC

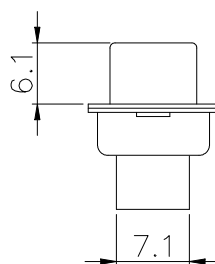
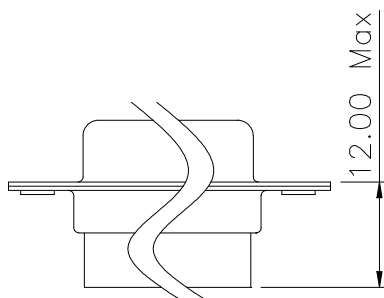
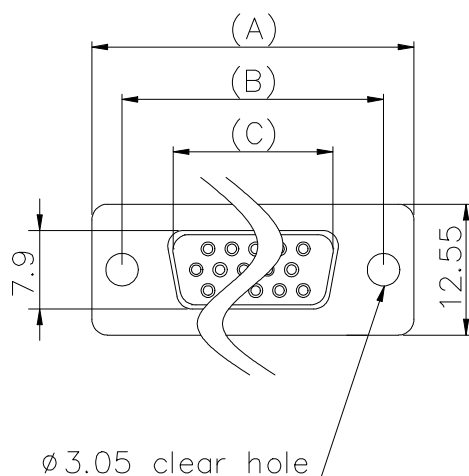
Current Rating: 3A

Dielectric Withstanding Voltage : 1000V AC for 1 minute

Operating Temperature : -55 $^{\circ}$ C to +105 $^{\circ}$ C**Materials :**

Housing : Glass-filled thermoplastic, UL94V-0

Shell : Steel, Tin plated

Dimensions :

Nb of Contacts	A	B	C
9	30,89	24,99	16,33
15	39,10	33,32	24,66
25	53,09	47,04	38,38
37	69,40	63,50	54,84

Part Numbers :

Nb of Contacts	Part Number
15	L177HRE15S
26	L177HRA26S
44	L177HRB44S
62	L177HRC62S

