

QSFP8-038-01-L-D-RA1

(0,80 mm) .0315"

QSFP8, QSFP8, QSFPK SERIES

QSFP CONNECTOR & CAGE

Mates with:

QSFP

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?QSFP8

Insulator Material:

LCP

Contact Material:

Phosphor Bronze

Ground Plane:

Phosphor Bronze


Plating:Au or Sn over 50 μ " (1,27 μ m) Ni**Current Rating (QSFP8/Card):**
1.6 A per pin
(1 pin powered per row)

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



Note: Some lengths, styles and options are non-standard, non-returnable.


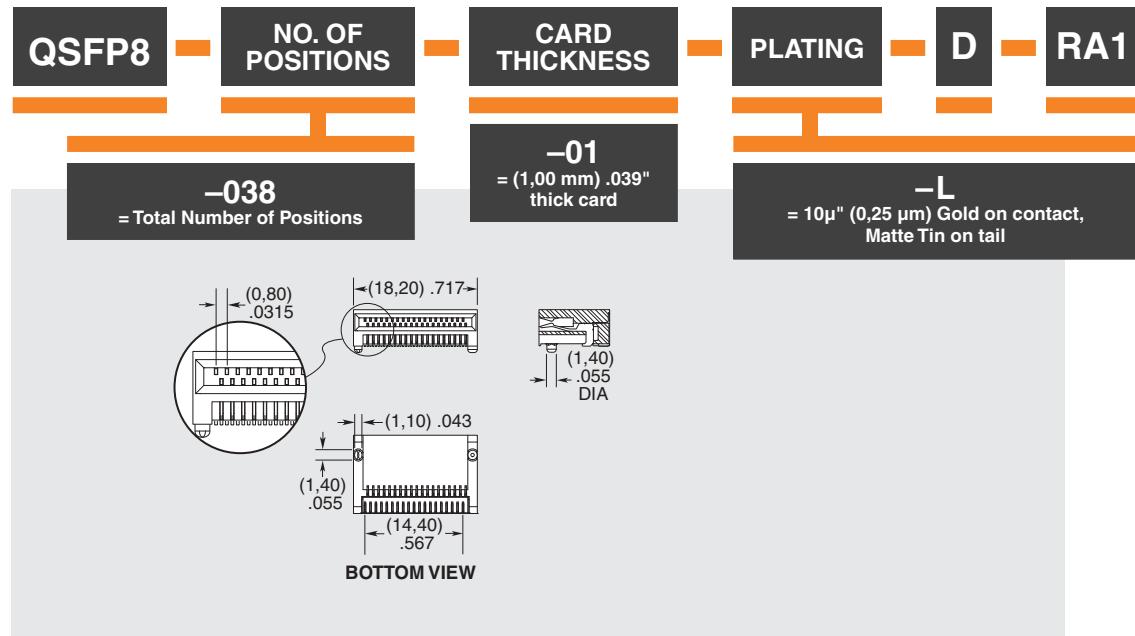
**Use with:** QSFP8

SPECIFICATIONS

For complete specifications see www.samtec.com?QSFP8 or www.samtec.com?QSFPK

TYPE**TERMINATION****OPTION****QSFP8**
= Cage**QSFPK**
= Cage and Connector Kit**-PF**
= Press Fit**-01**
= Without Heat Sink**-02**
= With Heat Sink**-03**
= With Heat Sink and clip packaged separately
(Recommended for cage press fit processing)

APPLICATION

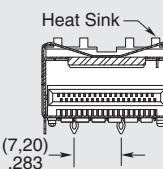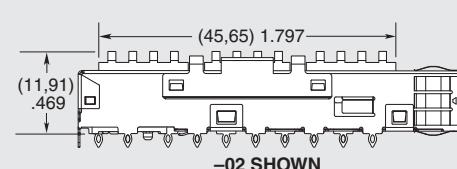

Note: Some sizes, styles and options are non-standard, non-returnable.