




SMA CONNECTORS

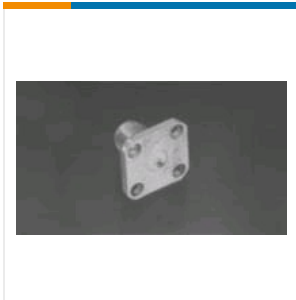

✓ Active

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

TE CONNECTIVITY (TE)
2052 3121 00
[AMP](#) | [SMA](#)

1052601-1
TE Internal Number: 1052601-1
Alias ID: 2052-3121-00

[Always EU RoHS/ELV Compliant](#)

Applies To **Printed Circuit Board**

Panel Mount **With**

Body Material **Stainless Steel**

Body Plating Finish **Plated**

Body Plating Material **Gold**

Product Drawings

[OSM HERMETICALLY SEALED MICROSTRIP TRANSITION](#)
PDF ([TIFF AVAILABLE](#))
English

[OSM HERMETICALLY SEALED MICROSTRIP TRANSITION](#)
PDF ([TIFF AVAILABLE](#))
English

CAD Files

[3D PDF](#)
PDF
3D

[Customer View Model](#)
2D_DXF.ZIP
English

[Customer View Model](#)
3D_IGS.ZIP
English

[Customer View Model](#)
3D_STP.ZIP
English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Applies To	Printed Circuit Board
RF Connector Type	SMA
Connector Style	Jack
PCB Mounting Orientation	Edge
Product Type	Connector - RF
Shrink Tubing	Without

	Retractable Collar	Without
Configuration Features	Snap-Lock	Without
Electrical Characteristics	50 Ohm	Yes
	75 Ohm	No
Body Features	Body Material	Stainless Steel
	Body Plating Finish	Plated
	Body Plating Material	Gold
	Body Style	Straight
Contact Features	Center Contact Plating Material	Gold
	Center Contact	With
	Center Contact Material	Beryllium Copper
	Captivated Contacts	With
Mechanical Attachment	Panel Mount	With
	Panel Mount Retention Type	Flanged
	Safety Wire Holes	Without
	Panel Attachment Style	Front Mount
	Number of Panel Mounting Holes	4
Dimensions	Length	.465 mm [.465 in]
Packaging Features	Packaging Method	Package
Other	Comment	Hermetically Sealed, With protective cap.
Product Compliance	Statement of Compliance PDF	
	VIEW ALL PRODUCT COMPLIANCE	