

Have a Question?
Chat with a Product
Information Specialist

What can we help you find?




583389-000 Product Details

Share

Print

Email

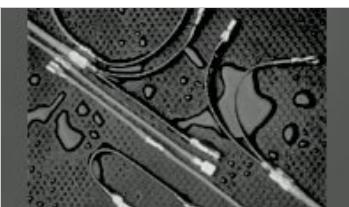

Active

Quick Disconnect Receptacles - Insulated

B-106-3633

583389-000

TE Internal Number: 583389-000

Product Highlights [View All](#)

- Proprietary Name = DuraSeal
- Receptacle Style = Straight
- Wire Range = 3.00-6.00² [12-10] mm [AWG]
- Mating Area Interface Dimensions = 6.35 x 0.81 mm
- Insulation Diameter = 6.35 [.250] Max. mm [in]

Pricing & Availability

Request Sample

Add to My Part List

Buy Product through Distributor

DocumentsFeaturesCompliance

Product Drawings
[Duraseal Push-On Receptacle](#) (PDF, English)

Product Specifications
Product Specification
[Installation Procedure for Duraseal Splices and Term...](#) (PDF, English)

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)
[View Part in Product Feature Selector](#)
[Check for Tooling](#)
Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed
