


OSMM CONNECTORS

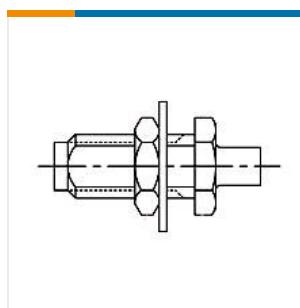

✓ Active

PRODUCT DRAWING

English

TE CONNECTIVITY (TE)
4004 7947 00
AMP

1058990-1
TE Internal Number: 1058990-1
Alias ID: 4004-7947-00

Always EU RoHS/ELV Compliant

Applies To **Cable**

50 Ohm **Yes**

75 Ohm **No**

Connector Style **Jack**

Cable Type **.047 Semi-Rigid**

Product Drawings

OSMM STRAIGHT BULKHEAD CABLEJACK

PDF [\(TIFF AVAILABLE\)](#)

English

OSMM STRAIGHT BULKHEAD CABLEJACK

PDF [\(TIFF AVAILABLE\)](#)

English

Instruction Sheets

Instruction Sheet (U.S.)

OSMM Bulkhead Feedthrough Cable Jack Direct Solder Attachment 1058990-1

TIF

English

OSMM Bulkhead Feedthrough Cable Jack Direct Solder Attachment 1058990-1

PDF

English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Applies To

Cable

Connector Style

Jack

Cable Type

.047 Semi-Rigid

Shrink Tubing

Without

Product Type

Connector - RF

Dielectric Material

PTFE

Electrical Characteristics

50 Ohm

Yes

75 Ohm

No

	Impedance (Ω)	50
Signal Characteristics	Frequency (GHz)	45
Body Features	Body Style	Straight
	Body Plating Material	Gold over Nickel
	Body Material	Stainless Steel
Contact Features	Center Contact Plating Material	Gold over Copper
	Center Contact Material	Beryllium Copper
Termination Features	Cable Termination Type	Solder
Mechanical Attachment	Mounting Type	Bulkhead
Product Compliance	Statement of Compliance PDF	
		VIEW ALL PRODUCT COMPLIANCE