


620-054
Strain Relief
Direct Coupling - Straight



**CONNECTOR
DESIGNATOR**

D
**DIRECT
COUPLING**

Product Series — **620 D S 054 M 16**
Connector Designator —
Angle and Profile — **S** = Straight
Shell Size (Table III) — **16**
Finish (Table II) —
Basic Part No. —

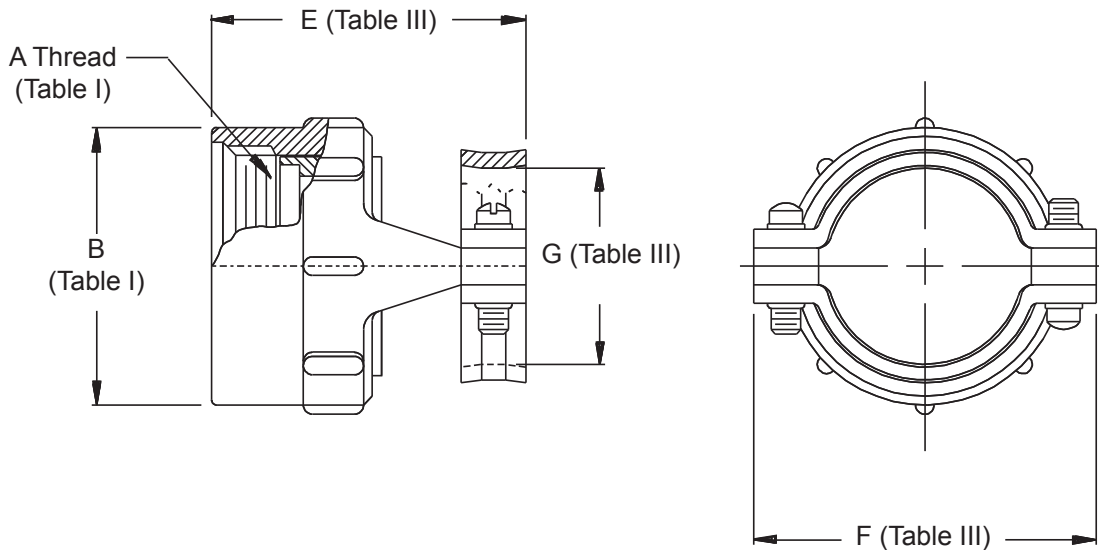

See inside back cover fold-out or pages 13 and 14 for Tables I and II.

TABLE III: CABLE ENTRY

Shell Size	E Max	F Max	G Dia Max Closed
08	1.120 (28.4)	.833 (21.2)	.187 (4.7)
10	1.120 (28.4)	.855 (21.7)	.187 (4.7)
12	1.120 (28.4)	1.016 (25.8)	.281 (7.1)
14	1.370 (34.8)	1.141 (29.0)	.325 (8.3)
16	1.370 (34.8)	1.203 (30.6)	.356 (9.0)
18	1.370 (34.8)	1.469 (37.3)	.456 (11.6)
20	1.370 (34.8)	1.469 (37.3)	.519 (13.2)
22	1.370 (34.8)	1.641 (41.7)	.519 (13.2)
24	1.370 (34.8)	1.750 (44.5)	.657 (16.7)

1. Cable Entry is defined as the accommodation entry for the wire bundle or cable. Dimensions are not intended for inspection criteria.
2. Metric dimensions (mm) are indicated in parentheses.