

(1,00mm) .03937"

CLM, MLE SERIES


ELP™
 EXTENDED LIFE PRODUCT

 10 year Mixed Flowing Gas with 30µ" Gold
 Call Samtec for maximum cycles

MLE-150-01-G-DV

MLE-120-01-G-DV

CLM-111-02-L-D

CLM-126-02-F-D

RUGGED RELIABLE MICRO SOCKETS

SPECIFICATIONS

 For complete specifications and recommended PCB layouts see www.samtec.com?CLM
Insulator Material:

Black LCP


Contact Material:

Phosphor Bronze

Plating: Au, Sn or SnPb

Current Rating:

3A @ 80°C ambient

Operating Temp Range:

-55°C to +125°C

Contact Resistance:

15 mΩ max

Insertion Depth:

Top Entry = (1,40mm) .055"

min., Bottom Entry = (2,41mm)

.095" min. (Add board

thickness for correct post OAL)

Insertion Force:

1.5oz (0,42N) average

Normal Force:

40 grams (0,39N) average

Withdrawal Force:

.75oz (0,21N) average

Max Cycles:

100 with 10µ" (0,25µm) Au

RoHS Compliant: Yes

Lead-Free Solderable: Yes

SMT Lead Coplanarity:

(0,10mm) .004" max (02-25)

(0,15mm) .006" max (26-50)


Note: Some lengths, styles

and options are non-standard,


non-returnable.

 Mates with:
 FTM, FTMH, MW


02 thru 50

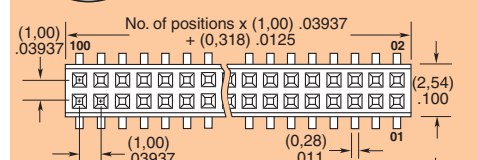

APPLICATION

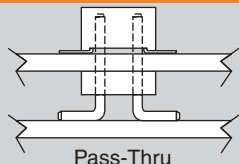

PIN/ROW	A
04-15	(3,56) .140
16-50	(7,11) .280

PLATING OPTION

-F
 = Gold flash on contact,
 Matte Tin on tail

-L
 = 10µ" (0,25µm)
 Gold on contact,
 Matte Tin on tail

OPTIONS

-BE
 = Bottom Entry
 (Required for bottom entry)

-K
 = (3,50mm) .138" DIA
 Polyimide film Pick & Place Pad
 (7 positions minimum)

-P
 = Pick & Place Pad
 (7 positions minimum)

-PA
 = Pick & Place Pad with
 integral Alignment Pin

-TR
 = Tape & Reel Packaging

APPLICATION SPECIFIC OPTION

- Alignment Pin available.
 - Other Gold plating options available.
- Call Samtec.

SPECIFICATIONS

 For complete specifications and recommended PCB layouts see www.samtec.com?MLE
Insulator Material:

Black LCP


Contact Material:

BeCu

Operating Temp Range:

-55°C to +125°C

Plating:

Au over 10µ" (0,25µm) Ni

Insertion Depth:

(1,63mm) .064" to (3,18mm)

.125" with (0,38mm) .015"

wipe, pass-through, or

(2,44mm) .096" minimum

for bottom entry

Insertion Force:

2.70oz (0,75N) average

Withdrawal Force:

0.50oz (0,14N) average

RoHS Compliant: Yes

Lead-Free Solderable: Yes

SMT Lead Coplanarity:

(0,10mm) .004" max (02-25)

(0,15mm) .006" max (26-50)



Note: Some lengths, styles

and options are non-standard,

non-returnable.

 Mates with:
 FTM, FTMH, MW


02 thru 50

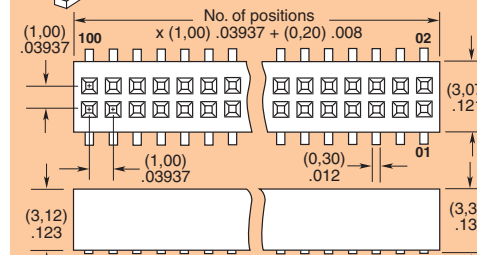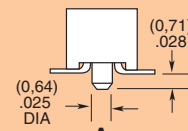
-G
 = 10µ" (0,25µm)
 Gold

-A
 = Alignment Pin
 (3 positions minimum)
 Metal or plastic at Samtec
 discretion.

OPTIONS

-K
 = (4,00mm) .1575" DIA
 Polyimide film Pick & Place Pad
 (5 positions minimum)

-P
 = Metal Pick & Place Pad
 (5 positions minimum)

-TR
 = Tape & Reel Packaging

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683