


1. 产品尺寸图Product Dimension Drawing

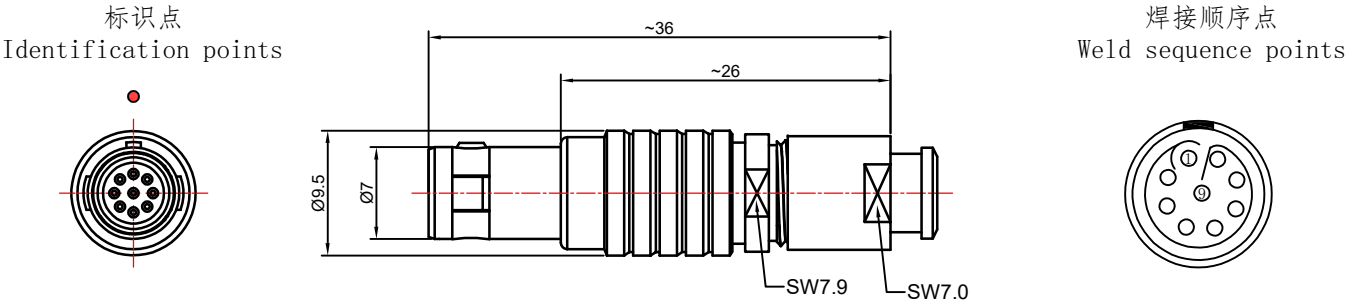

2. 产品电器参数Product electrical parameters


防护等级 (Ingress protection)	IP50(头座插合时When the headstand is plugged in)
插拔测试 (Plugging and unplugging test)	<5000次
产品耐温 (The product is temperature resistant)	-55° C / +250° C
盐雾腐蚀 (Salt Spray Corrosion)	>72 hr
测试电压 (kV rms) 针芯-针芯	0.6
测试电压 (kV rms) 针芯-外壳	0.5
额定电流Current rating	2A
湿度 (最大值) Humidity (max)	<=95 (at 60 deg C/140F)
屏蔽 (分钟) Shielding (min)	75 dB(10MHz)
屏蔽 (分钟) Shielding (min)	100 g (6 ms)
振动 Vibration	15 g (10Hz-1000Hz)

3. 环境及表面处理产品特性Environmental and surface treatment product characteristics

外壳材料 Housing material	金属件铜合金镀镍镀铬 (Metal parts: copper alloy nickel plated and chrome plated)
导体材料 Conductor material	锡青铜镀金(Pewter bronze gilding)
绝缘体材料 Insulator material	PPS (可选PEEK) PPS (optional PEEK)

4. 线缆参数Cable parameters

固定类型 Fixed type	电缆夹头 (Cable chucks)
护套电缆外径 (mm) Sheath cable outer diameter (mm)	4.3-5.2mm

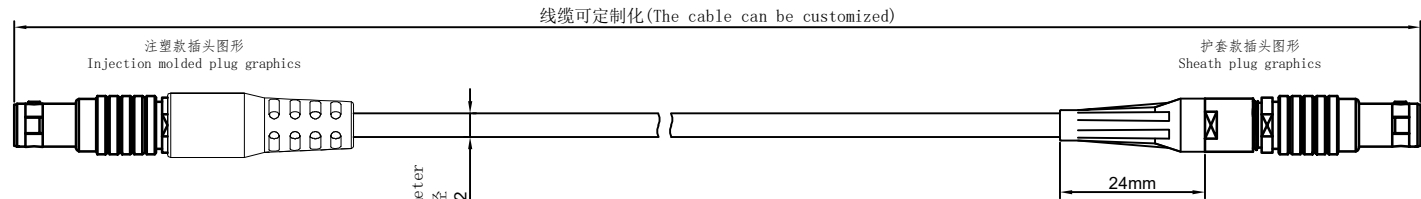

1: 连接器组装生产所有公差通常为0.1mm,2: 插座直接拧入螺纹孔中, 螺纹 +0.05mm 1: All tolerances are usually 0.1mm for connector assembly production, 2: The socket is screwed directly into the threaded hole, the thread is +0.05mm	东莞市通瑞电子科技有限公司 CN-TRRE CONNECTE Dongguan Tongrui Electronic Technology Co., Ltd www.cntrre.com	单芯图纸Single-core drawings 单位unit:mm 修改revise:A0 视图view:
	0B系列直式插头0B Series Straight Plug	型号Model BR.FGG.0B.109.CSAD52Z