


1. 产品尺寸图Product Dimension Drawing

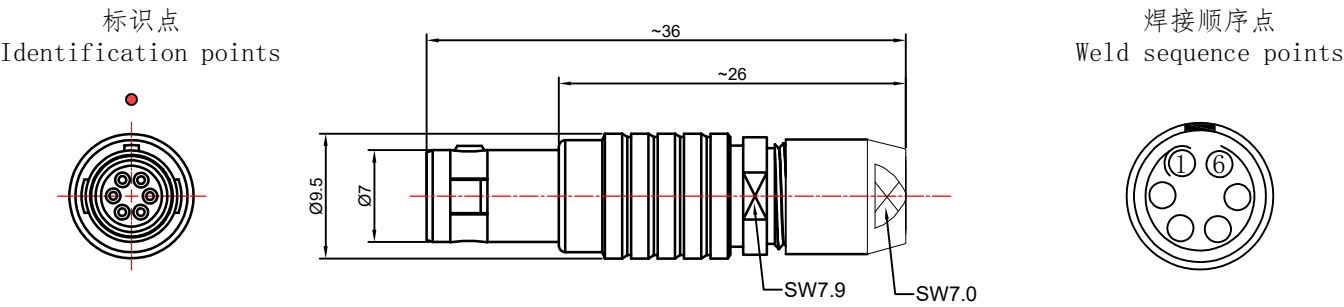

2. 产品电器参数Product electrical parameters

|                                             |                                             |
|---------------------------------------------|---------------------------------------------|
| 防护等级 (Ingress protection)                   | IP50(头座插合时When the headstand is plugged in) |
| 插拔测试 (Plugging and unplugging test)         | <5000次                                      |
| 产品耐温 (The product is temperature resistant) | -55° C / +250° C                            |
| 盐雾腐蚀 (Salt Spray Corrosion)                 | >72 hr                                      |
| 测试电压 (kV rms) 针芯-针芯                         | 0.85                                        |
| 测试电压 (kV rms) 针芯-外壳                         | 0.65                                        |
| 额定电流Current rating                          | 2.5A                                        |
| 湿度 (最大值) Humidity (max)                     | <=95 (at 60 deg C/140F)                     |
| 屏蔽 (分钟) Shielding (min)                     | 75 dB(10MHz)                                |
| 屏蔽 (分钟) Shielding (min)                     | 100 g (6 ms)                                |
| 振动 Vibration                                | 15 g (10Hz-1000Hz)                          |

3. 环境及表面处理产品特性Environmental and surface treatment product characteristics

|                          |                                                                           |
|--------------------------|---------------------------------------------------------------------------|
| 外壳材料 Housing material    | 金属件铜合金镀镍镀铬<br>(Metal parts: copper alloy nickel plated and chrome plated) |
| 导体材料 Conductor material  | 锡青铜镀金(Pewter bronze gilding)                                              |
| 绝缘体材料 Insulator material | PPS (可选PEEK) PPS (optional PEEK)                                          |

4. 线缆参数Cable parameters

|                                                 |                     |
|-------------------------------------------------|---------------------|
| 固定类型 Fixed type                                 | 电缆夹头 (Cable chucks) |
| 护套电缆外径 (mm)<br>Sheath cable outer diameter (mm) | 4.3-5.2mm           |

