



CXCC4

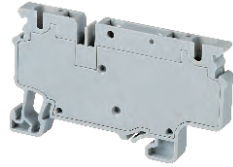


CPD1



 CPF



CPF(L)

 

Dimensions

Width	6 mm	6 mm	6 mm	6 mm
Length	65.4 mm	28 mm	28 mm	28 mm
Height w/ DIN Rail	35 x 7.5 mm 35 x 15 mm	61.3 mm 68.8 mm		
Weight per piece	10.2 g	3.8 g	3.8 g	4.2 g

Technical Data/Ratings

Approvals	  	  	  	  				
Wire Size (solid stranded)	24-10 AWG	0.2-4 mm ²	24-10 AWG	0.2-4 mm ²	24-10 AWG	0.2-4 mm ²	24-10 AWG	0.2-4 mm ²
Voltage Rating	600 V	1000V AC/DC	600 V	1000V AC/DC	600 V	1000V AC/DC	600 V	1000V AC/DC
Current Rating	*	*	1 A	1 A	10 A	10 A	10 A	10 A
Insulation Material	Polyamide 66		Polyamide 66		Polyamide 66		Polyamide 66	

Carrier Specifications

Component Type	Component carrier base	Plug module with diode Diode Type IN4007	Plug module for 5x20 mm fuse	Plug module for 5x20 mm fuse with LED indicator
LED Indicator Voltage	—	—	—	6-60V AC/DC 110-240V AC/DC

Installation Instructions

Wire Stripping Length	10 mm	—	—	—
Screwdriver	Flat Head 0.6 x 3.5 mm	—	—	—

Terminal Blocks

	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
Grey (standard)	CXCC4	50	CPD1	50	CPF	50	CPF(L)6-60V CPF(L)110-240V	50 50

Accessories

	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.	Cat. No.	Std. Pk.
DIN Rail	2511120 CA701-15/S	20 10	—	—	—	—	—	—
End Stop	CA702 CA802 CA103	50 50 50	—	—	—	—	—	—
Shorting Link/ Jumpers	2 pole JX4/2 3 pole JX4/3 4 pole JX4/4 8 pole JX4/8 10 pole JX4/10 16 pole JX4/16	100 50 50 50 10 10	—	—	—	—	—	—
Test Plug	TX4	50	—	—	—	—	—	—
Marking Tag Warning Label	MT6 SWL4	100 50	MT6 —	100 —	MT6 —	100 —	MT6 —	100 —

* Current rating is based on plug used.