

SUMMARY

Wires

Low voltage 13



Image is for illustrative purpose only

Series	RR
Termination type	Female crimp
IP rating	50
AWG wire size	32.00 - 28.00
Cable Ø	1.00 - 4.00 mm
Status	active
Matching parts	FGG.RR.313.ALC40

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	EGG*: Fixed receptacle, key (G) or key (A)
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), blue
Weight	2.84 g

Performance

Configuration	RR.313 : 13 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	


Specifications

Contact Type: Crimp
Test voltage (kV rms) Contact-contact: 0.6

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

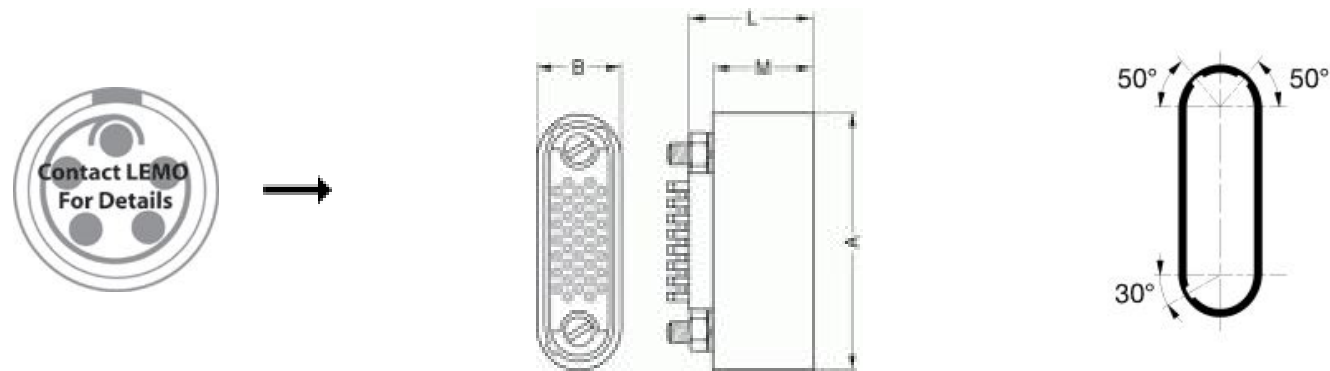

Dimensions

	A	B	C	E	G	L
mm.	37	15	51	4.5	3.2	39
in.	1,46	0,59	2,01	0,18	0,13	1,54

RECOMMENDED BY LEMO

Tools

- Crimp Tool:
[DPC.91.701.V](#)
- Crimp settings:
AWG/Selector = 28-30-32/4-3-3
- Positionner:
[DCE.91.050.0VM](#)
- Extractor:
[DCF.91.050.2LT](#)
- Replacement contact:
EGG.00.654.ZZM

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.