

IE-BS-V01M-SCRJ2SC-SM-C**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com



Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (Ethernet/IP), RJ45 metal insert incl.
SC insert

General ordering data

Version	Flange FO, IP67, Version 1, coupling from SCRJ on 2*SC, Singlemode
Order No.	1963440000
Type	IE-BS-V01M-SCRJ2SC-SM-C
GTIN (EAN)	4032248645534
Qty.	10 pc(s).

IE-BS-V01M-SCRJ2SC-SM-C

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	36.6 mm	Depth (inches)	1.441 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	62.7 g		

Temperatures

Operating temperature -40 °C...70 °C

Environmental Product Compliance

REACH SVHC	SCIP	67cf1078-beca-4687-860b-dc475a6ec24a
Lead 7439-92-1		

General data

Colour	Miscellaneous	Connection 1	SC
Connection 2	SCRJ	Description of article	Version 1, coupling from SCRJ on 2*SC
Fibre type	Singlemode	Housing main material	Zinc diecast
Insertion loss	≤ 0.5 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 40 dB

General standards

Connector standard IEC 61076-3-106 Var.
1, IEC 61754-4, IEC
61754-24

Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ECLASS 9.0	19-17-01-22
ECLASS 9.1	19-17-01-22	ECLASS 10.0	19-17-01-22
ECLASS 11.0	19-17-01-22	ECLASS 12.0	19-17-01-22

Approvals

ROHS Conform

IE-BS-V01M-SCRJ2SC-SM-C**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

Technical data

info@weidmueller.com

www.weidmueller.com

Downloads

Approval/Certificate/Document of Conformity	GOST Approval PROFINET Manufacturer's Declaration	www.weidmueller.com
Engineering Data	CAD data – STEP	
Engineering Data	WSCAD	
Product Change Notification	Technical change to Bulkhead Variant 1 (Metal) - EN Technical change to Bulkhead Variant 1 (Metal) - DE 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technical change to Bulkhead Variant 1 (Metal)	
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual	
Catalogues	Catalogues in PDF-format	
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN	

IE-BS-V01M-SCRJ2SC-SM-C

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0


Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Drawings

Installation cut-out

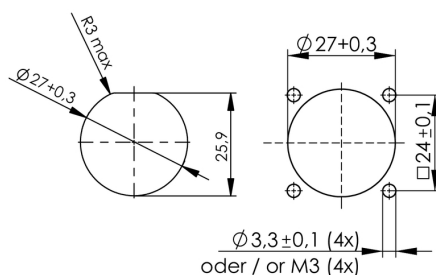

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws