

CATEGORIES

Sockets contacts

MATING PIN DIAMETER

All

TERMINATION

PCB solder without tail

CONTACT LENGTH

All

CONTACT OUTER DIAMETER

1.1 to 1.5 (.043" to .059")

For more information or to request assistance, please contact sales@precidip.com

[« Back to search results](#)

YOUR SELECTED PRODUCT

Screw-machined Contacts

01418

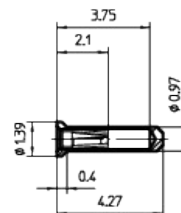
Socket contacts

For other versions than the listed available standard types, please contact PRECI-DIP

SPECIFICATIONS:

Socket contact without solder tail / SMD socket contact

- Materials: body brass, contact clip BeCu
- Electrical contact resistance max. 20 milliohms
- Mechanical life min. 500 cycles

 Metric

AVAILABLE STANDARD TYPES

Ordering Part Number		Plating Body	Plating Clip	Insertion	Extraction	Dia.Gauge	Max Current
01418-83-1110	RoHS	5µm Sn	0.75µm Au	1.00 N	0.40 N	0.43 mm	3.0 A
01418-87-1110	RoHS	5µm Sn	Flash Au	1.00 N	0.40 N	0.43 mm	3.0 A

CAD CATALOG

Literature
Catalog
CAD catalog

ABOUT PRECI-DIP

Career
Contact
Events

OTHER INFO

Feedback
Legal disclaimer
Cross references

NEWSLETTER

Stay informed!

Company

Last name, first name

Email

subscription