

KG series

Power rocker switches

Distinctive features and specifications



- ☐ Protected rocker
- ☐ Illuminated or non-illuminated
- ☐ VDE (EN 61058-1) approved
- ☐ Sealed to IP65


ELECTRICAL SPECIFICATIONS

- Current/voltage rating :
 - functions 1 (ON-OFF) and 6 (ON-ON) : 15A 12VDC, 10A 24VDC max., 10mA 14VDC min.
 - functions 4 (ON ON ON) and 4-1R (ON ON MOM) : 8A 12VDC, 5A 24VDC max.
 - other functions : 10A 12VDC, 8A 24VDC max.
- Initial contact resistance : 10 mΩ max. at 1A 2VDC
- Insulation resistance : 1.000 MΩ min. at 500VDC
- Dielectric strength : 2.000 Vrms 50 Hz min. between terminals
- Electrical life : 10.000 cycles min.
- Mechanical life : 2 position models : 100.000 cycles min.
3 position models : 30.000 cycles min.

ENVIRONMENTAL SPECIFICATIONS

- Degree of protection : IP65 according to IEC 60529
- Shock resistance : 100 g according to IEC 512-4, test 6c
- Vibration resistance : 10-500 Hz - 10 g according to IEC 512-4, test 6d
- Salt spray resistance : 96 hours according to IEC 512-6, test 11f
- Operating temperature : 2 position models : -40°C to + 85°C
3 position models : -10°C to + 65°C

MATRIX MOUNTING

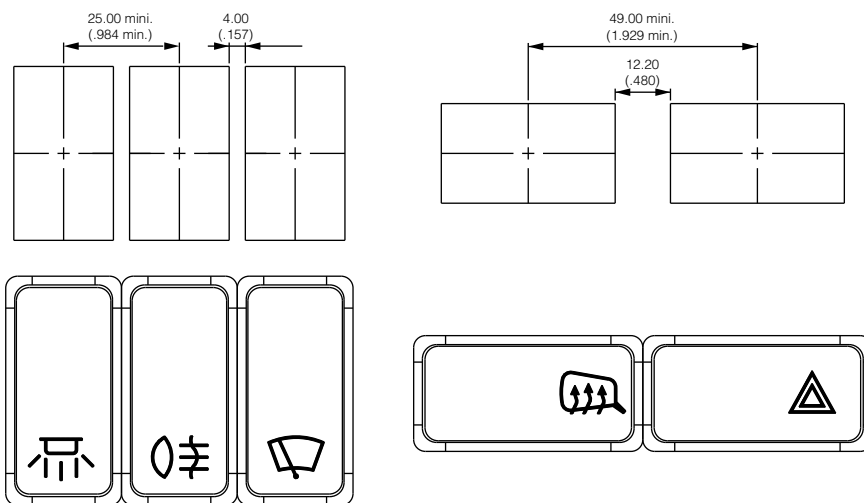

MATERIALS

- Case : thermoplastic UL94-V0
- Terminals : brass, silver plated
- Contacts : silver grain
- Contact roller : brass, nickel plated

AGENCY APPROVAL



12(4)A 250VAC
T85/55°C

EN 61058-1

Availability : double pole models, functions ON-OFF and ON-ON.

Marking : to order switches marked VDE, add "VDE" at the end of model number.



Packaging unit : 40 pieces




Sealing boots are available to protect the switches against dust and water. They are presented in section H.

Dimensions : First dimensions are in mm while inches are shown as bracketed numbers.

KG series


Power rocker switches

Case

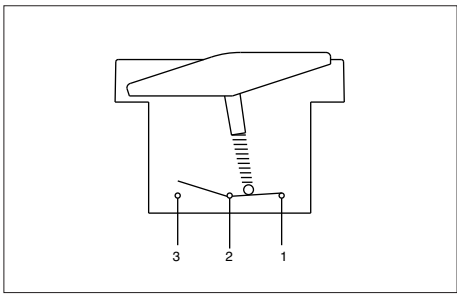


PANEL CUT-OUT

Panel thickness :
0,8 mm to 4,6 mm
Recommended thickness :
between 2 mm and 3,5 mm


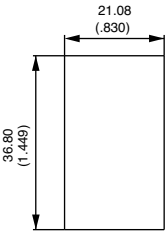


MODEL STRUCTURE

 

Single pole	Double pole
KG31	KG41
	KG44*
	KG44-1R*
KG35	KG45
KG36	KG46
KG37	KG47
KG38	KG48
KG39	KG49



2-3		1-2
5-6		4-5
ON	-	OFF
ON	ON	ON
ON	ON	MOM
MOM	-	ON
ON	-	ON
MOM	OFF	MOM
ON	OFF	MOM
ON	OFF	ON

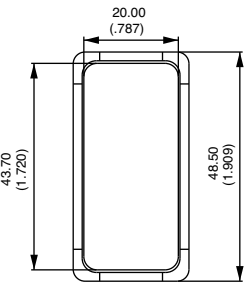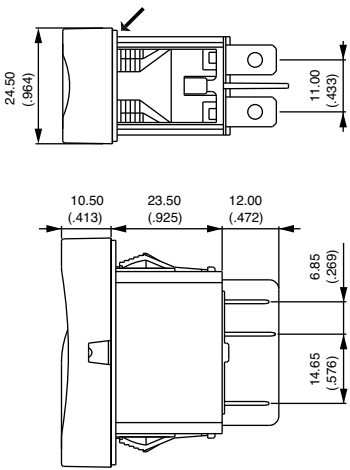


→ Flat seal

* Function 4 : single pole in double pole case

 
TERMINALS

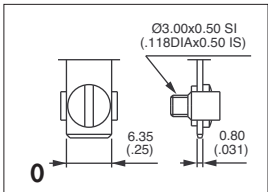

Screw

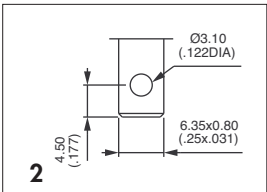


Solder lug / quick-connect

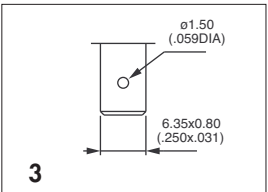

Quick-connect


Terminals 1 to 6
are marked on the case.

 Side A : terminals 1 and 4
Side B : terminals 3 and 6



Side B

 CONTACT MATERIALS




A Silver grain

KG series

Power rocker switches


Lamps

 BEZEL



2 Black, sealed to IP65

 
LAMPS



Complete each enlarged box with one of the codes listed below.

X	Without lamp
A	6V LED red
B	6V LED green
C	6V LED yellow
D	12V LED red
E	12V LED green
F	12V LED yellow
G	18V LED red
H	18V LED green
I	18V LED yellow





J	24V LED red
K	24V LED green
L	24V LED yellow
M	Neon 125V
N	Neon 250V
O	Filament 6V
P	Filament 12V
R	Filament 24V
S	Fluorescent 220V
T	Fluorescent 110V

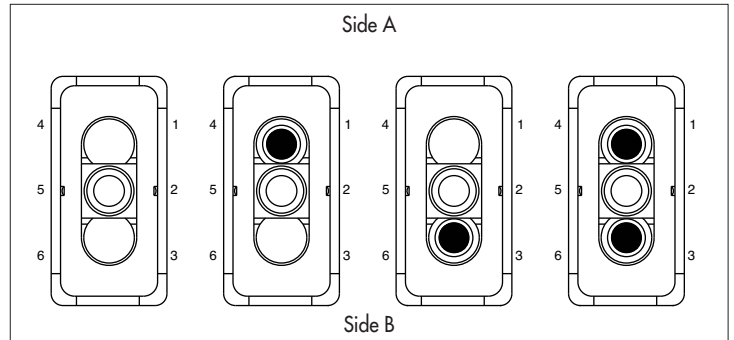




White and blue LEDs : on request.

LAMP WIRING

The lamp wiring diagram is shown on the case.

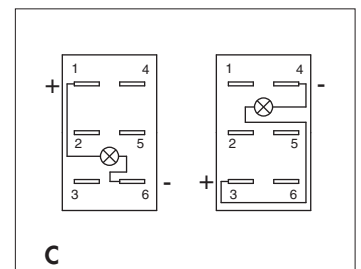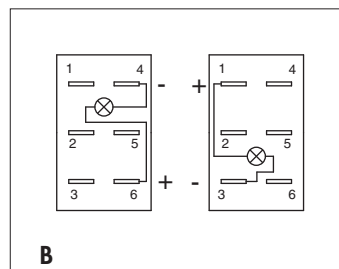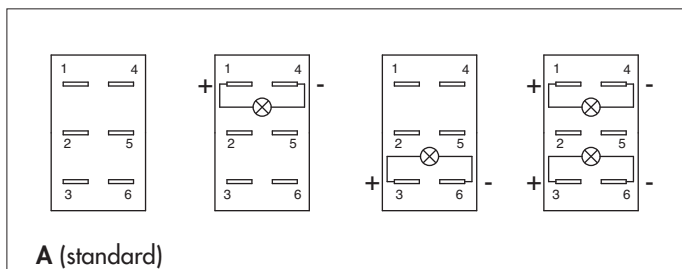 


Note : If not available, terminals are added to connect the LED.

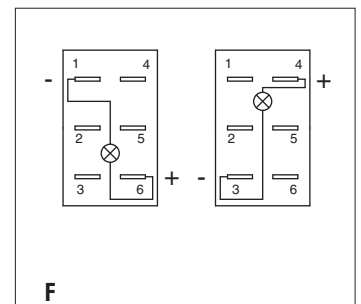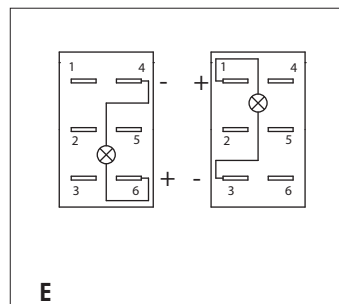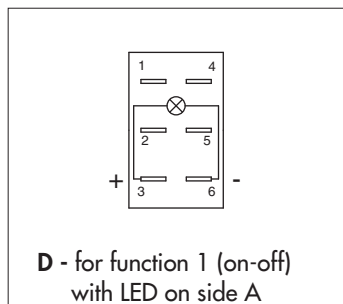

To order case only (without rocker), finish your order number with the lamp wiring code.

 
ROCKER COLOUR



1	Blue
1/4	Dark blue
2	Black
3	Green
4	Grey

5	Yellow
6	Red
7	Ivory
9	Orange

 ROCKER SHAPE



1

Full rocker



4

Opening on side A



6

Opening on side B



 
8

Opening on sides A and B

Other rocker shapes on customer specifications : on request.



To order rocker only (without case), begin the order number with code KGR, then follow the order format from "rocker colour" until the end of the options.

LENS COLOUR



Complete each enlarged box with one of the codes listed below.

X	No lens
1	Blue *
3	Green *
6	Red
9	Orange
B	White
T	Translucent

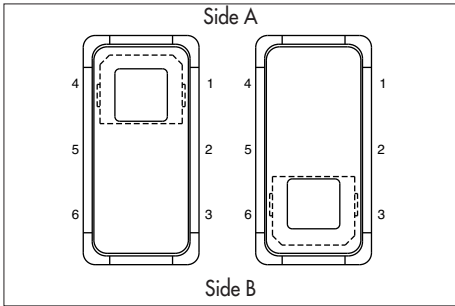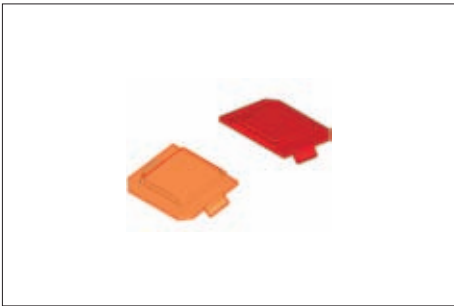

* Blue or green lens recommended with fluorescent lamp.

To order lenses only, begin the order number with the codes :
KGLA for lens A and KGLB for lens B,
then follow the order format from "lens colour" until the end of the options.

 
KG series

Power rocker switches

Marking


MARKING

If no marking required, leave all boxes blank.




Select one option from each of the tables below.

MARKING METHOD	
C	Hot stamping

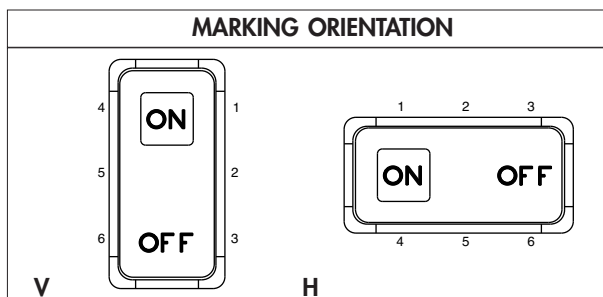

Other orientations :
on request

 SYMBOLS



XX No symbol

Available symbols : see end of section D.

Marking colour

White marking for black rockers - Black marking for colour rockers

Other : on request.

Marking area

For illuminated versions. The symbol will be included in the hatched area.

