


C-FILTER D-SUB HIGH DENSITY

Solder pin – Straight – Precision machined contacts



RoHS compliant – CSA listed, File No.: LR 115000-1 – UL listed, File No.: E202784


SOCKET CONNECTOR

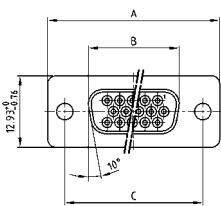

No. of pos.	A -0.76	B -0.25	C
15	31.19	16.46	25.00 ^{+0.12} _{-0.13}
26	39.52	24.79	33.30 ^{+0.15} _{-0.10}
44	53.42	38.50	47.04 ^{+0.13} _{-0.10}
62	69.70	54.96	63.50 ^{+0.13} _{-0.10}

PCB layout: Kat1i1T9A

Mounting style: Threaded rear spacer

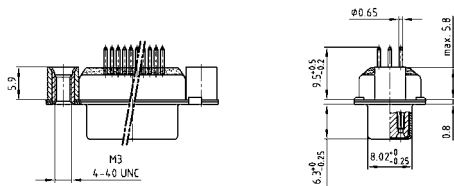

C-FILTER D-SUB HIGH DENSITY

Solder pin – Straight – Precision machined contacts

ORDER DATA

Capacitance 370 pF

SOCKET CONNECTOR			PLUG CONNECTOR		
No. of pos.	Mounting style	Part Number	No. of pos.	Mounting style	Part Number
15	4-40 UNC Threaded rear spacer	242 A 18220 X	15	4-40 UNC Threaded rear spacer	241 A 16620 X
26	4-40 UNC Threaded rear spacer	242 A 18230 X	26	4-40 UNC Threaded rear spacer	241 A 16630 X
44	4-40 UNC Threaded rear spacer	242 A 18240 X	44	4-40 UNC Threaded rear spacer	241 A 16640 X
62	4-40 UNC Threaded rear spacer	242 A 18250 X	62	4-40 UNC Threaded rear spacer	241 A 16650 X
15	M3 Threaded rear spacer	242 A 18300 X	15	M3 Threaded rear spacer	241 A 16700 X
26	M3 Threaded rear spacer	242 A 18310 X	26	M3 Threaded rear spacer	241 A 16710 X
44	M3 Threaded rear spacer	242 A 18320 X	44	M3 Threaded rear spacer	241 A 16720 X
62	M3 Threaded rear spacer	242 A 18330 X	62	M3 Threaded rear spacer	241 A 16730 X
15	4-40 UNC Front/Threaded rear spacer	242 A 18380 X	15	4-40 UNC Front/Threaded rear spacer	241 A 16780 X
26	4-40 UNC Front/Threaded rear spacer	242 A 18390 X	26	4-40 UNC Front/Threaded rear spacer	241 A 16790 X
44	4-40 UNC Front/Threaded rear spacer	242 A 18400 X	44	4-40 UNC Front/Threaded rear spacer	241 A 16800 X
62	4-40 UNC Front/Threaded rear spacer	242 A 18410 X	62	4-40 UNC Front/Threaded rear spacer	241 A 16810 X
15	M3 Front/Threaded rear spacer	242 A 18460 X	15	M3 Front/Threaded rear spacer	241 A 16860 X
26	M3 Front/Threaded rear spacer	242 A 18470 X	26	M3 Front/Threaded rear spacer	241 A 16870 X
44	M3 Front/Threaded rear spacer	242 A 18480 X	44	M3 Front/Threaded rear spacer	241 A 16880 X
62	M3 Front/Threaded rear spacer	242 A 18490 X	62	M3 Front/Threaded rear spacer	241 A 16890 X

Capacitance 830 pF

SOCKET CONNECTOR			PLUG CONNECTOR		
No. of pos.	Mounting style	Part Number	No. of pos.	Mounting style	Part Number
15	4-40 UNC Threaded rear spacer	242 A 18260 X	15	4-40 UNC Threaded rear spacer	241 A 16660 X
26	4-40 UNC Threaded rear spacer	242 A 18270 X	26	4-40 UNC Threaded rear spacer	241 A 16670 X
44	4-40 UNC Threaded rear spacer	242 A 18280 X	44	4-40 UNC Threaded rear spacer	241 A 16680 X
62	4-40 UNC Threaded rear spacer	242 A 18290 X	62	4-40 UNC Threaded rear spacer	241 A 16690 X
15	M3 Threaded rear spacer	242 A 18340 X	15	M3 Threaded rear spacer	241 A 16740 X
26	M3 Threaded rear spacer	242 A 18350 X	26	M3 Threaded rear spacer	241 A 16750 X
44	M3 Threaded rear spacer	242 A 18360 X	44	M3 Threaded rear spacer	241 A 16760 X
62	M3 Threaded rear spacer	242 A 18370 X	62	M3 Threaded rear spacer	241 A 16770 X
15	4-40 UNC Front/Threaded rear spacer	242 A 18420 X	15	4-40 UNC Front/Threaded rear spacer	241 A 16820 X
26	4-40 UNC Front/Threaded rear spacer	242 A 18430 X	26	4-40 UNC Front/Threaded rear spacer	241 A 16830 X
44	4-40 UNC Front/Threaded rear spacer	242 A 18440 X	44	4-40 UNC Front/Threaded rear spacer	241 A 16840 X
62	4-40 UNC Front/Threaded rear spacer	242 A 18450 X	62	4-40 UNC Front/Threaded rear spacer	241 A 16850 X
15	M3 Front/Threaded rear spacer	242 A 18500 X	15	M3 Front/Threaded rear spacer	241 A 16900 X
26	M3 Front/Threaded rear spacer	242 A 18510 X	26	M3 Front/Threaded rear spacer	241 A 16910 X
44	M3 Front/Threaded rear spacer	242 A 18520 X	44	M3 Front/Threaded rear spacer	241 A 16920 X
62	M3 Front/Threaded rear spacer	242 A 18530 X	62	M3 Front/Threaded rear spacer	241 A 16930 X