

Han 4HC-Halterung

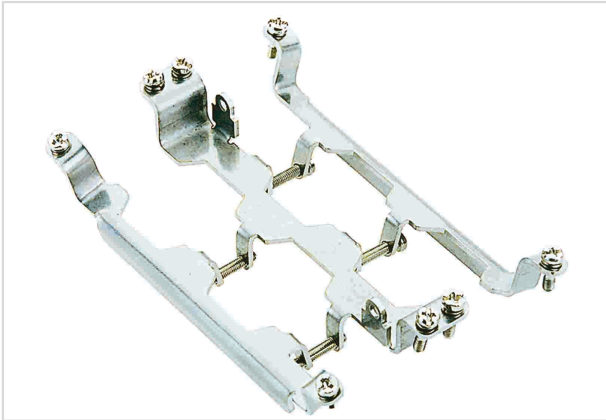


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 9955
Specification	Han 4HC-Halterung
HARTING eCatalogue	https://b2b.harting.com/09110009955

Identification

Category	Accessories
Series of hoods/housings	Han® M
Type of accessory	Frame
Description of the accessory	for male inserts
	for female inserts
	4x HC 350 contacts + 2x Han® Q 5/0 in a bulkhead mounted housing

Version

Size	48 B
------	------

Technical characteristics

Tightening torque	0.5 Nm Fixing screws M3
	0.25 Nm Fixing screws Han® Q 5/0
	1.5 Nm Cross-tying screws

Material properties

Material (accessories)	Metal
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No
California Proposition 65 substances	Yes



Pushing Performance

Material properties

California Proposition 65 substances	Nickel
--------------------------------------	--------

Commercial data

Packaging size	1
Net weight	69.54 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440210 Fixing element for industrial connectors