


Stud Type Block

Altech DIN rail mounting Stud Type Terminal Blocks are preferred for the connections that are subjected to very severe vibrations.


The wire is crimped to a ring / fork type lug and is screwed on to the flat current bar in terminal.

Jumpering can be achieved with the aid of external jumpers. The jumpers are insulated to make them shock proof. The terminal blocks have marker holding recess to accommodate marking tags.


It is recommended to use protective covers in transparent plastic because assemblies of these terminals blocks are not fully covered.

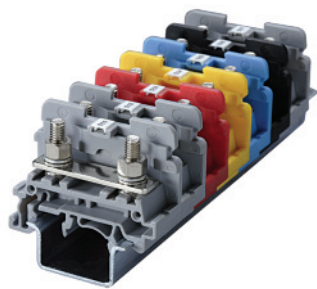

CSTSN4U

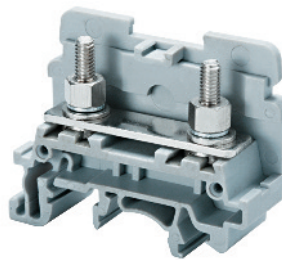

CSTSN5U

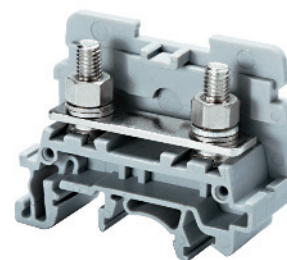

Terminal Width	17 mm			17 mm		
Height x Length	39.5 x 50 mm			39.5 x 50 mm		
Stripping Length	12 mm			12 mm		
Insulation Material	Polyamide 6.6			Polyamide 6.6		
Type of Connection	2 screw connection for M4 ring/fork lugs			2 screw connection for M5 ring/fork lugs		
Approvals	  			  		
Wire Range	22-6 AWG	1.5-10 sq.mm	22-6 AWG	22-4 AWG	1.5-16 sq.mm	22-4 AWG
Voltage Rating	600 V	1000 V	600 V	600 V	1000 V	600 V
Current Rating	65 A	57 A	65 A	80 A	76 A	80 A
Torque	14 lb-in	1.2 Nm	14 lb-in	25 lb-in	2.0 Nm	25 lb-in
Other Approvals						

Terminal Block

End Plate	
-----------	---

DIN Rail
for ordering information
refer to pages 90-91

End Stop for ordering information refer to page 92	
--	---

Protective Cover for covering	2 Terminal 3 Terminal
----------------------------------	--------------------------

Protective Cover in Length	100 mm 200 mm 300 mm
-------------------------------	----------------------------

Insulated Removable Jumpers	2 way 3 way 4 way
--------------------------------	-------------------------

Insulated Permanent Jumpers	2 way 3 way 4 way
--------------------------------	-------------------------

Marking Tags	
--------------	---

Cat. No.	Std. Pk.
----------	----------

CSTSN4U	100
----------------	-----

EPCSTSN5U	50
-----------	----

	
---	--

CA702	50
CA802	50

CSTSPC1	100
CSTSPC1-1	100

CSTSPC1-2	10
CSTSPC1-3	10
CSTSPC1-4	10

CA514/1-2	100
CA514/1-3	50
CA514/1-4	50

CA514/3-2	100
CA514/3-3	50
CA514/3-4	50

MT2B4	100
-------	-----

Cat. No.	Std. Pk.
----------	----------

CSTSN5U	100
----------------	-----

EPCSTSN5U	50
-----------	----

	
---	---

CA702	50
CA802	50

CSTSPC1	100
CSTSPC1-1	100

CSTSPC1-2	10
CSTSPC1-3	10
CSTSPC1-4	10

CA514/1-2	100
CA514/1-3	50
CA514/1-4	50

CA514/3-2	100
CA514/3-3	50
CA514/3-4	50

MT2B4	100
-------	-----

COLOR BLOCKS		
(other than standard grey)		
When ordering please add color suffix to Cat. No.		
Example for color Red: Cat.No./R		
Color	Ordering Suffix	
Red	R	
Yellow	Y	
Blue	BU	
Green	G	
Consult Altech for availability:		
Orange	O	
Beige	BG	
Dark Brown	DB	
Black	BL	
White	W	