

D-SUB SHIELDED CAP

Metal design – Shielded – Fastening screws




RoHS compliant


DESCRIPTION

- Shielded cap protecting against EMI/RFI
- Material: Steel tin plated
- Mounting style:
with 4-40 UNC screw and clip

SOCKET CONNECTOR

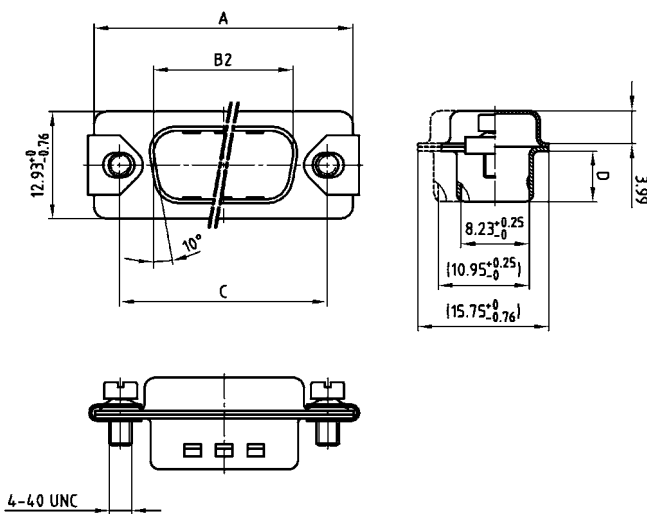

PLUG CONNECTOR

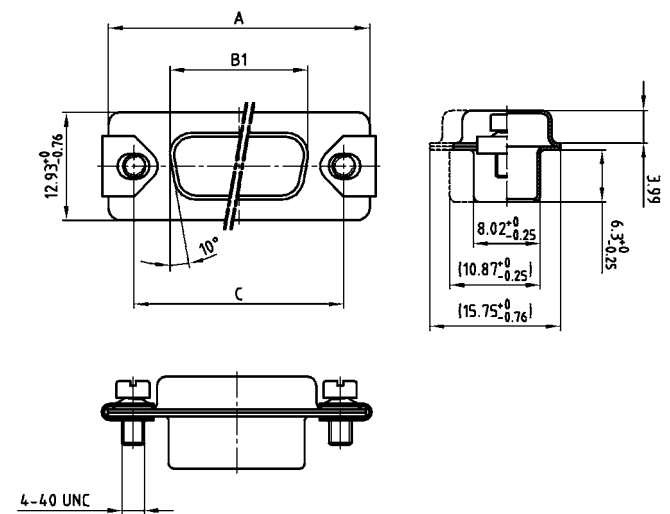

50-pos.= Dim. in (..)

No. of pos.	A-0.76	B1-0.25	B2-0.25	C	D-0.3
09	31.19	16.46	16.79	25.00 ±0.12	6.12
15	39.52	24.79	25.12	33.30 ±0.15 ±0.10	6.12
25	53.42	38.50	38.84	47.04 ±0.13	5.99
37	69.70	54.96	55.30	63.50 ±0.13	5.99
50	67.31	52.55	52.68	61.10 ±0.14 ±0.11	5.99

ORDER DATA

SHIELDED CAP FOR SOCKET CONNECTOR			SHIELDED CAP FOR PLUG CONNECTOR		
No. of pos.	Design 4-40 UNC	Part Number	No. of pos.	Design 4-40 UNC	Part Number
09	Metal/Screw and clip	165X16719X	09	Metal/Screw and clip	165X16769X
15	Metal/Screw and clip	165X16729X	15	Metal/Screw and clip	165X16779X
25	Metal/Screw and clip	165X16739X	25	Metal/Screw and clip	165X16789X
37	Metal/Screw and clip	165X16749X	37	Metal/Screw and clip	165X16799X
50	Metal/Screw and clip	165X16759X	50	Metal/Screw and clip	165X16809X