

RoHS

General tolerances(mm)

0 ~ 3	>3 ~ 6	>6 ~ 10	>10 ~ 18	>18 ~ 30	>30 ~ 50	>50 ~ 80	>80 ~ 120	>120 ~ 180	>180 ~ 250	>250 ~ 315	>315 ~ 400	>400 ~ 500	>500	0.1/10
±0.12	±0.18	±0.22	±0.26	±0.31	±0.37	±0.57	±0.80	±0.93	±1.05	±1.15	±1.60	±2.20	±2.50	±2°

VER	MARK	PR. BY	DESCRIPTION	DATE

Product model	PIN	A	B	C	D
DA381-261C1-2PG213	2X2	8.86	3.81	8.46	3.81
DA381-261C1-3PG213	2X3	12.67	7.62	12.27	7.62
DA381-261C1-4PG213	2X4	16.48	11.43	16.08	11.43
DA381-261C1-5PG213	2X5	20.29	15.24	19.89	15.24
DA381-261C1-6PG213	2X6	24.10	19.05	23.70	19.05
DA381-261C1-7PG213	2X7	27.91	22.86	27.51	22.86
.....					
DA381-261C1-24PG213	2X24	3.81xN/2+1.24	3.81x(N/2-1)	3.81xN/2+0.84	3.81x(N/2-1)

UL Standard	B	C	D
Rated Voltage(V)/Current(A)	300/8	/	300/8
IEC Standard			
Overvoltage Category/Pollution Degree	III/3	III/2	II/2
Rated Voltage(V)/Current(A)	/	/	250/7
Rate Impulse Voltage(KV)	/	/	2.5
Pitch(mm)/Poles	3.81/N=04~48P		
Operating temperature(*C)	-40~+105		
Conform to RoHS	Yes		


4	Cover	PA66	UL94V-0
3	Pin 2	Copper Alloy	Sn Plated
2	Pin 1	Copper Alloy	Sn Plated
1	Housing	PA66	UL94V-0
ITEM	NAME OF PART	MATERIAL	NOTES

GENERAL TOLERANCES
UNLESS SPECIFIED



深圳市华明通电子有限公司
Shenzhen Huamingtong Electronics Co., Ltd

PART NO.	TITLE: Socket-type terminal		
DA381-261C1-NPG213			
DESIGN: James	CUSTOMER	SIZE	UNITS
CHED: Talen		A4	MM
APPD: Sophia		SCALE	SHEET
		N:A	1/1

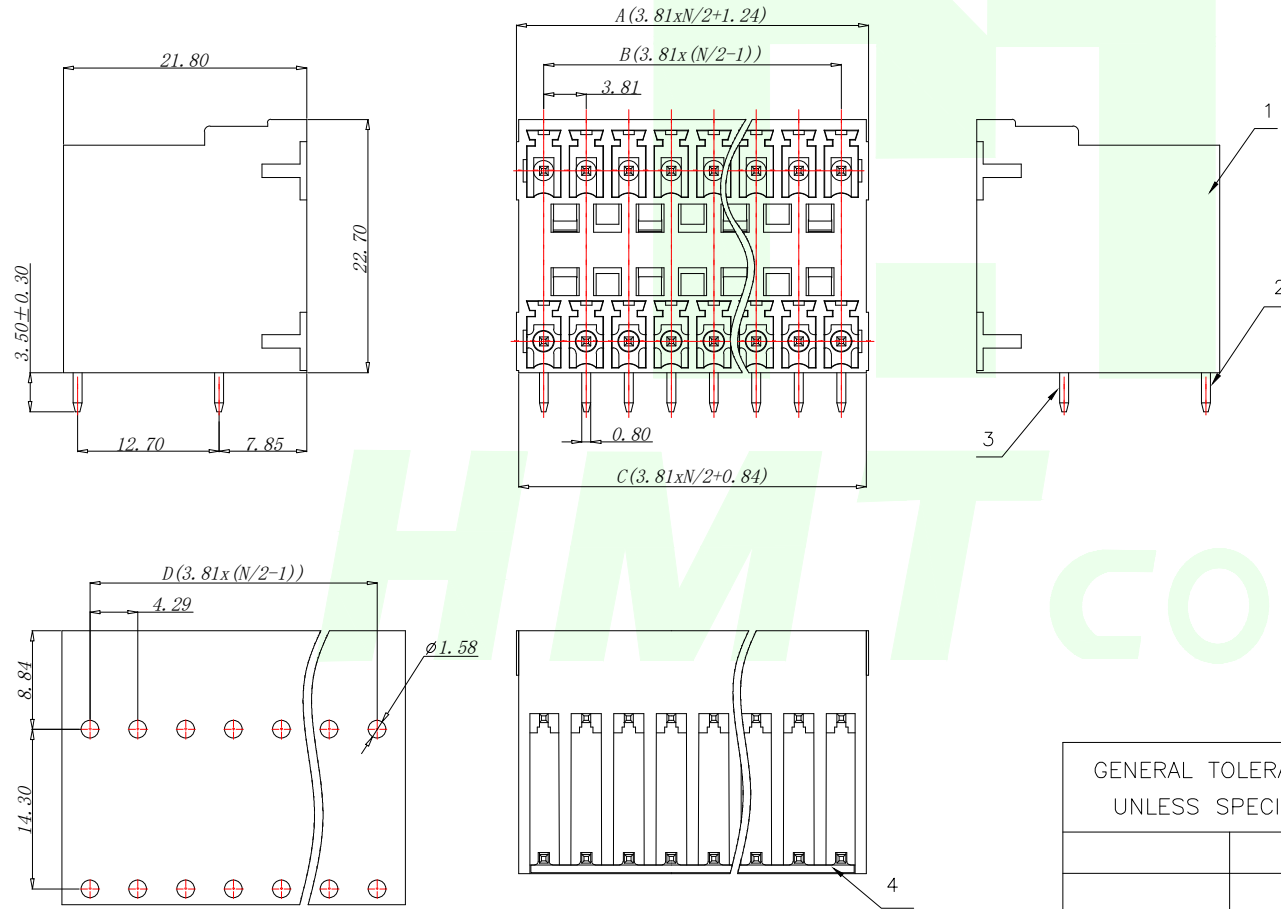

PCB LAYOUT