


Coaxial Cable Connector 16_MCX-50-2-104/111_N

Description

Right angle cable plug

Interface standards
IEC 60169-36_CECC 22220

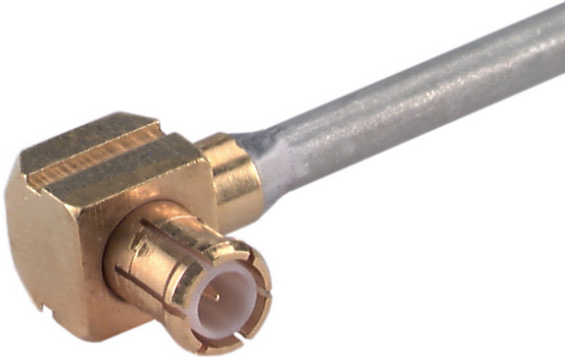

Technical Data

Electrical Data

Impedance	50 Ω		
Interface frequency max.	6 GHz		
Frequency range	DC to 2.5 GHz	2.5 to 4 GHz	4 to 6 GHz
Return loss	30 dB	25 dB	22 dB

Mechanical Data

Centre contact	soldered
Outer contact	soldered
Weight	0.0008 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Body	Brass	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00006447
Catalogue drawing	DOU-00006449
Assembly instruction	DOC-0000180001

Ordering Information

Bulk 100 pcs package	16_MCX-50-2-104/111_NH
----------------------	------------------------

Additional Information

Suitable cables	EZ_86_TP_M17
-----------------	--------------