

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

<b>Series</b>	0B
<b>Termination type</b>	No contacts / Accessory
<b>IP rating</b>	0
<b>AWG wire size</b>	0.00 - 0.00
<b>Cable Ø</b>	3.00 - 3.40 mm
<b>Status</b>	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

<b>Shell Style/Model</b>	GMA*: Bend relief White
<b>Keying</b>	No keying
<b>Housing Material</b>	Silicone elastomer VMQ
<b>Variant</b>	B : White
<b>Weight</b>	.42 g

### Performance

**Configuration**

**Insulator**

**Rated Current**


### Others

Temp (min / max): -60°C / +200°C

Temperature range in water steam: +140°C

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

## DRAWINGS

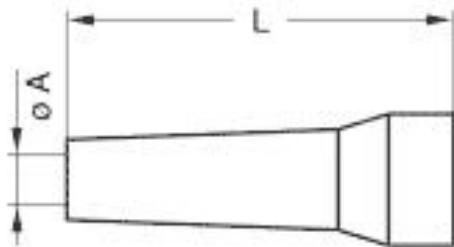

No keying

### Dimensions

	A	L
mm.	3.0	27
in.	0,12	1,06

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.