

SUMMARY

Wires

Low	19
High	0
Coax	0
Triax	0
Quad	0
Fiber	0
Fluidic	0



Image is for illustrative purpose only

Download

[Request a quote](#)

[Catalog](#)

Series	C
Termination type	Female print 90° PCB
IP rating	50
Cable Ø	0.00 - 0.00 mm
Matching parts	CAB.M19.GLA.C52G
Status	active
Alternative part	

TECHNICAL DETAILS

Mechanics

Shell Style/Model	CK*: Fixed receptacle with two nuts with 90° contacts (back panel mounting)
Keying	3 keys (alpha=0, gamma=60; Plug: male contacts; Receptacle: female contacts)
Housing Material	PSU (Polysulfone), gray
Cable Fixing	Ø 0 - 0 mm
Variant	
Weight	10.06 g

Performance

Configuration	2P.M19 : 19 Low V.
Insulator	
Rated Current	5 Amps

Specifications

Test voltage (kV rms) Contact-contact:	1.4
Air clearance min. (mm) or Creepage distance min. (mm):	0.6


LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Others

- F ret (min): 150 N
- F ret (max): 250 N
- Steam sterilization: 20 times
- IP Rating: 50

DRAWINGS

Draws

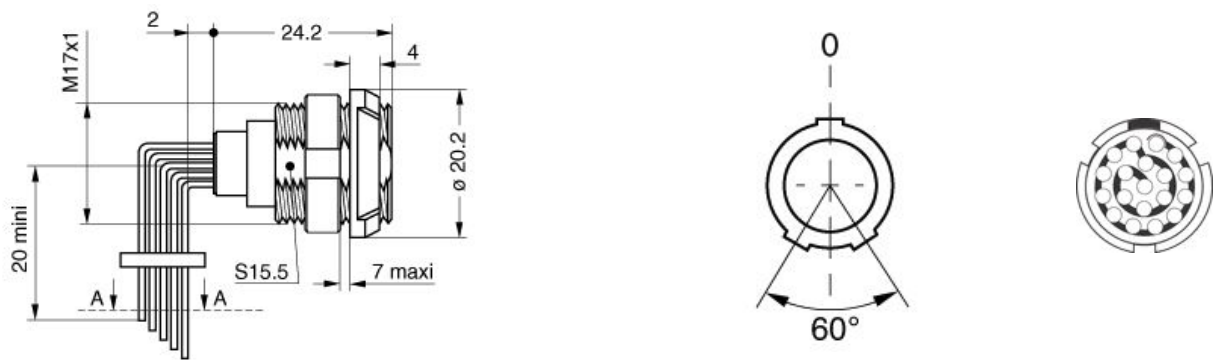

Dimensions

	A	N	a
mm.	20.2	24.2	2
in.	0,80	0,95	0,08

RECOMMENDED BY LEMO

Tools

None

Cables

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.