

SUMMARY

Wires

Low voltage 13



Image is for illustrative purpose only

Series	RR
Termination type	Female crimp
IP rating	50
AWG wire size	32.00 - 28.00
Cable Ø	1.00 - 4.00 mm
Status	active
Matching parts	FGG.RR.313.GLC40

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	PHG*: Free receptacle, cable collet key (G) or key (A), with cable collet
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), gray
Weight	3.94 g

Performance

Configuration	RR.313 : 13 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	



Specifications

Contact Type: Crimp
Test voltage (kV rms) Contact-contact: 0.6

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

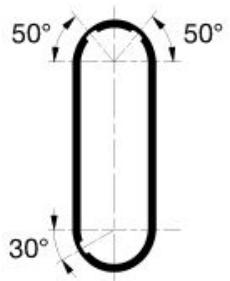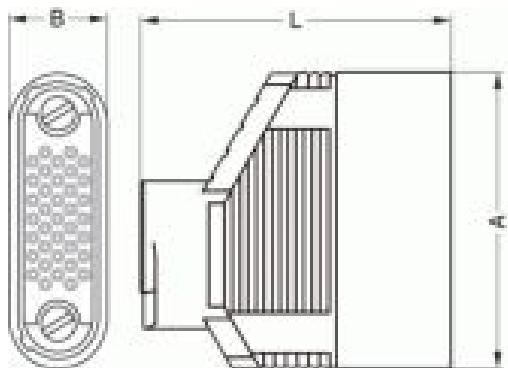

RECOMMENDED BY LEMO

Tools

Crimp Tool:	DPC.91.701.V
Crimp settings:	AWG/Selector = 28-30-32/4-3-3
Positionner:	DCE.91.050.0VM
Extractor:	DCF.91.050.2LT
Replacement contact:	EGG.00.654.ZZM

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.